


E43223



Coaxial pipe for level sensors

LR COAX TUBE NPT L1200

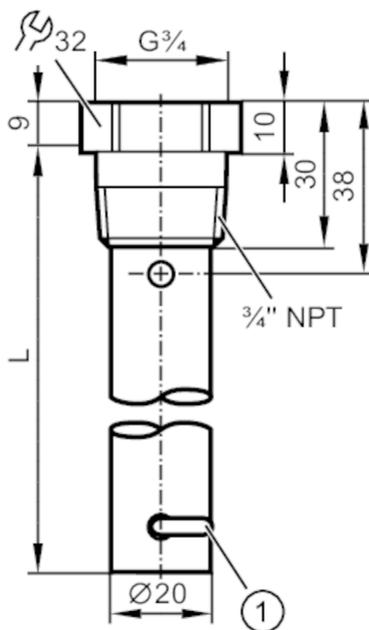

1 fixing bracket for centring piece

Application

Design		for level sensors LR
Medium temperature	[°C]	-40...200
Pressure rating	[bar]	16
Vacuum resistance	[mbar]	-1000

Mechanical data

Weight	[g]	645
Materials		Coaxial pipe: stainless steel (304/1.4301); Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (301/1.4310)
Sensor connection		threaded connection G 3/4 internal thread
Process connection		threaded connection 3/4" NPT external thread
Length L	[mm]	1200

Remarks

Pack quantity		1 pcs.
---------------	--	--------