


Wirable socket

SDOGM120MSSFKPG

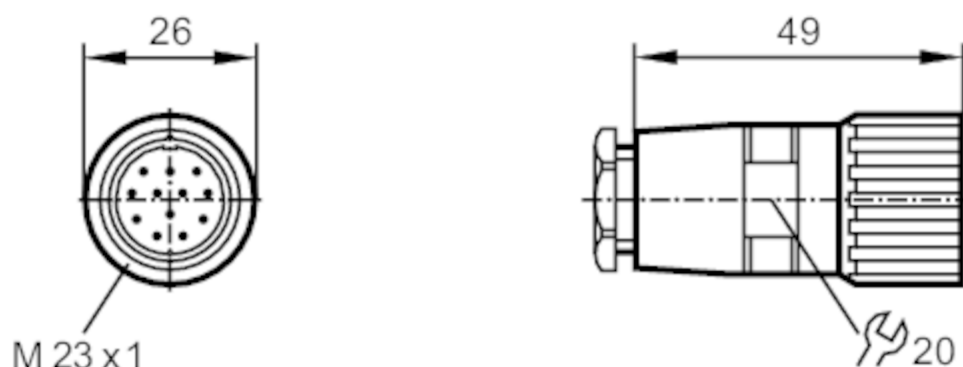

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	7.5

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Weight	[g]	77
Dimensions	[mm]	26 x 26 x 49
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

soldering: ...1 mm²; Cable sheath: Ø 10...14 mm

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

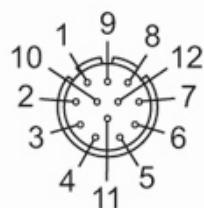

E10448



Wirable socket

SDOGM120MSSFKPG

Connection

