


E10844



Jumper cable with valve plug


VVDAC041MSS00,3A03STAH030VAS

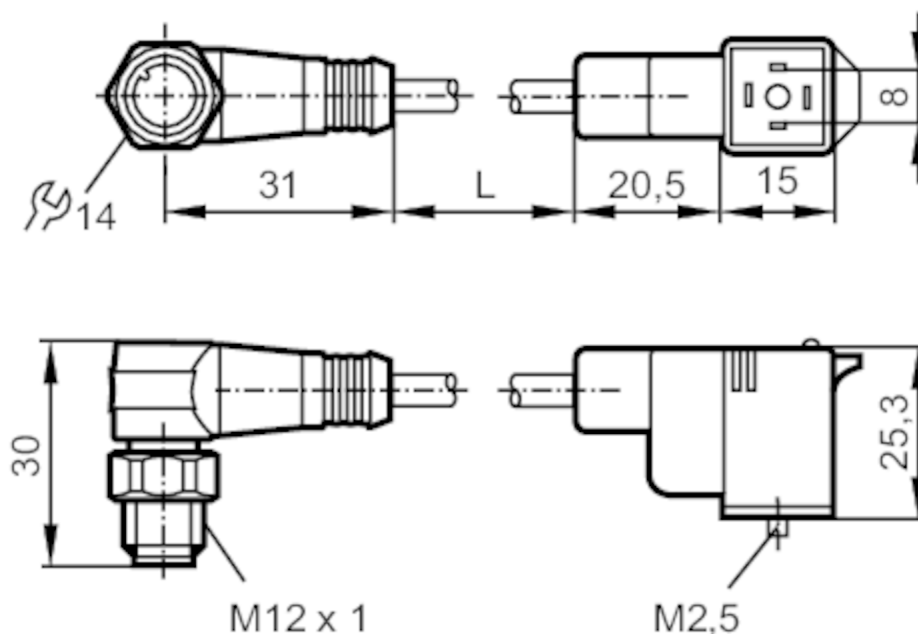

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overtoltage protection	yes; (VDR)	
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Weight	[g]	45.7
Materials	TPU	
Moulded-body material	TPU	
Material nut	stainless steel (316L/1.4404)	
Displays / operating elements		
Display	operation	1 x LED, yellow
Accessories		
Items supplied	screw	
	panel for labelling	
Remarks		
Pack quantity	1 pcs.	

VVDAC041MSS00,3A03STAH030VAS

 Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: stainless steel (316L/1.4404); Tightening torque: 0.5 Nm



Connection

