




Wirable socket


SDOGK190MSSFKPG

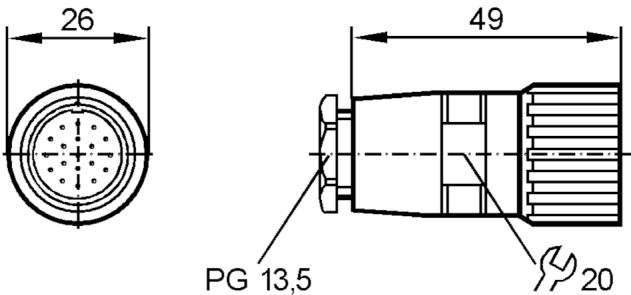

| Electrical data         |      |                      |
|-------------------------|------|----------------------|
| Operating voltage       | [V]  | 10...30 DC           |
| Max. current load total | [A]  | 7.5                  |
| Operating conditions    |      |                      |
| Ambient temperature     | [°C] | -25...90             |
| Protection              |      | IP 65                |
| Mechanical data         |      |                      |
| Weight                  | [g]  | 82.4                 |
| Dimensions              | [mm] | 26 x 26 x 49         |
| Materials               |      | brass nickel-plated  |
| Moulded-body material   |      | brass, nickel-plated |
| Material nut            |      | brass, nickel-plated |
| Remarks                 |      |                      |
| Pack quantity           |      | 1 pcs.               |

| Electrical connection                           |  |
|-------------------------------------------------|--|
| soldering: ...1 mm²; Cable sheath: Ø 10...14 mm |  |

| Electrical connection - socket                                                                  |  |
|-------------------------------------------------------------------------------------------------|--|
| Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated |  |

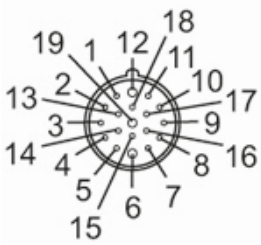

# E10887



## Wirable socket

SDOGK190MSSFKPG

### Connection

