


Adapter plug

ESTGH040MSS0,08E04 (M16)

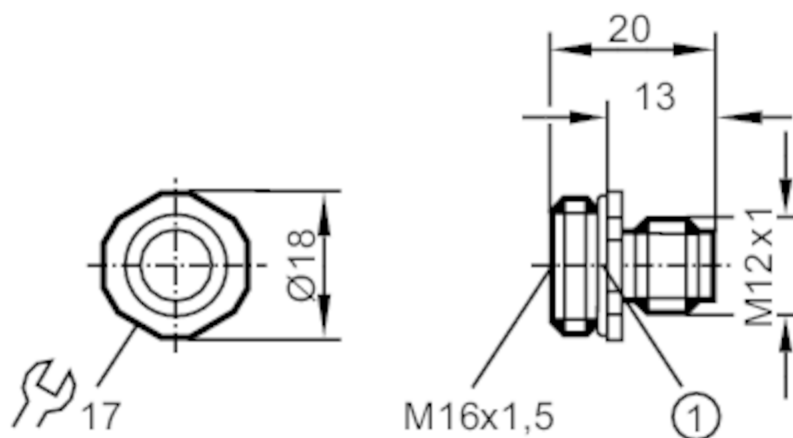

1 O-ring



Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	30.743
Mounting thread		M16 x 1,5
Materials		diecast zinc nickel-plated
Moulded-body material		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11528



Adapter plug

ESTGH040MSS0,08E04 (M16)

Electrical connection

Cable: 0.08 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white