


E30436



Jumper cable with valve plug

PLUG M12 - DIN VALVE FORM A

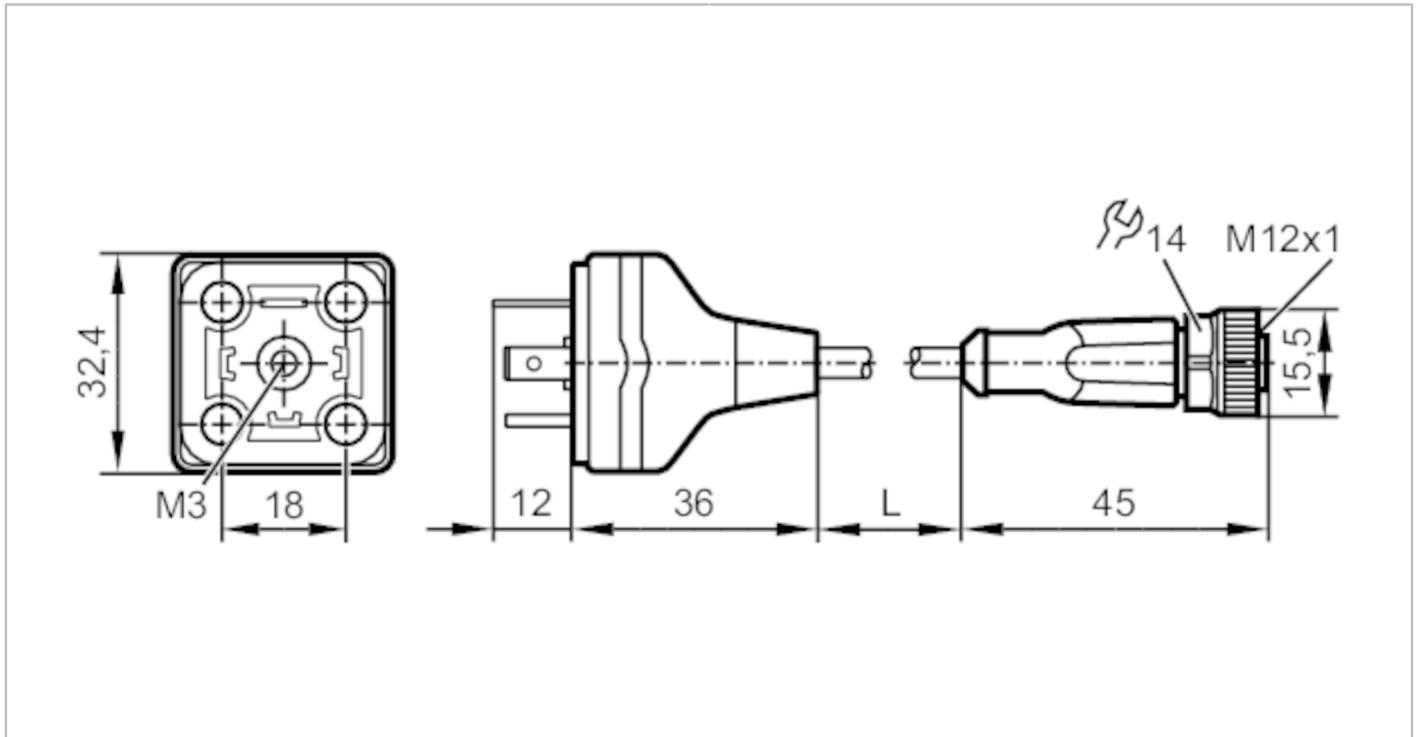

Application	
Special feature	Free from silicone; Halogen-free
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 50 AC / < 60 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 65
Mechanical data	
Weight [g]	66.7
Moulded-body material	TPU
Material nut	brass, nickel-plated
Sealing material	FKM
Remarks	
Pack quantity	1 pcs.

E30436




Jumper cable with valve plug

PLUG M12 - DIN VALVE FORM A

Electrical connection - plug


Connector: 1 x valve type A DIN, straight; Moulded body: TPU, black; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

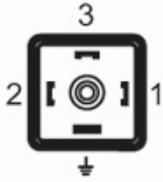

Electrical connection

Cable: 0.4 m, PUR, Halogen-free, black, Ø 5.5 mm; 5 x 0.50 mm²

Connection

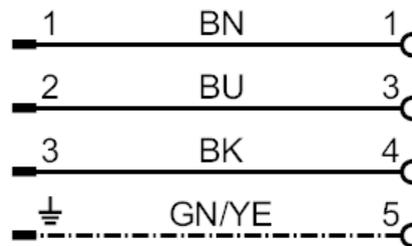

Core colours :
BK = black
BN = brown
BU = blue
GN/YE = green/yellow

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Sealing: FKM; Tightening torque: 0.6...1.5 Nm

