


Thermowell for temperature sensors

THERMOWELL, D6/1,5"CLAMP/L=150

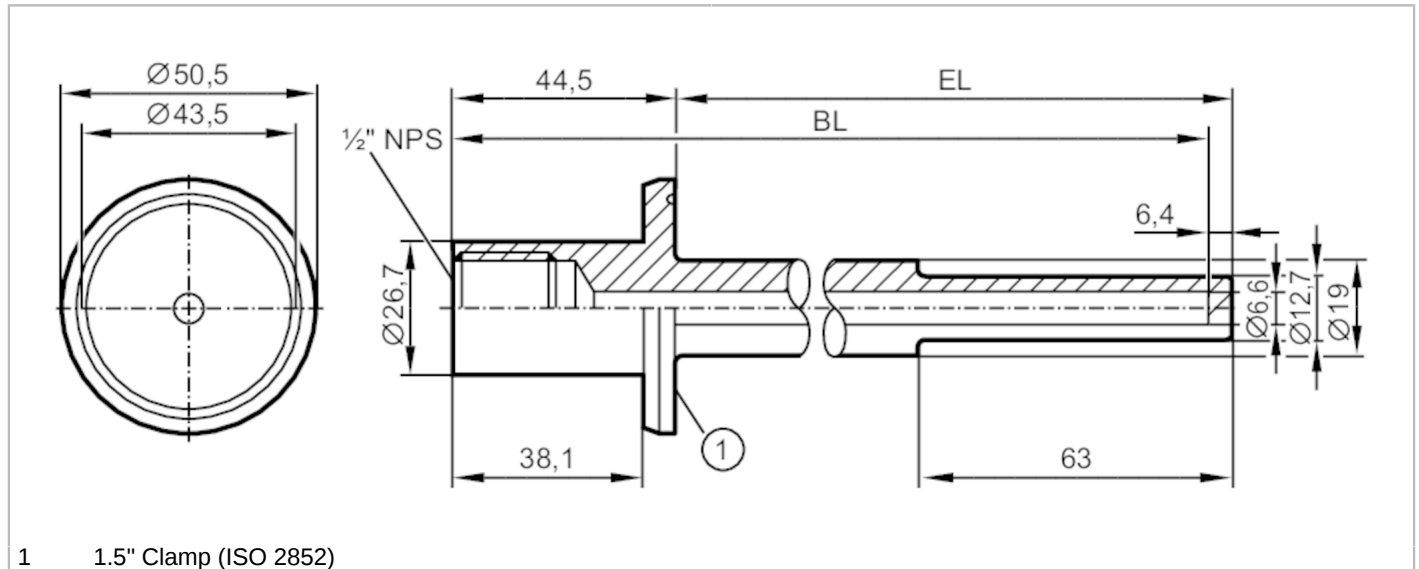

EC 1935/2004 EHEDG Certified


Application

Design	for temperature sensors EL = 150 mm
Pressure rating [bar]	25

Mechanical data

Weight [g]	353
Materials	stainless steel (316L/1.4404)
Sensor connection	1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT
Process connection	Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)
Surface characteristics Ra/Rz of the wetted parts	≤ 0.6 / -
Installation length EL [mm]	115
Bore length BL [mm]	152.4

Remarks

Pack quantity	1 pcs.
---------------	--------