




## Thermowell for temperature sensors

THERMOWELL, D6/2"CLAMP/L=230

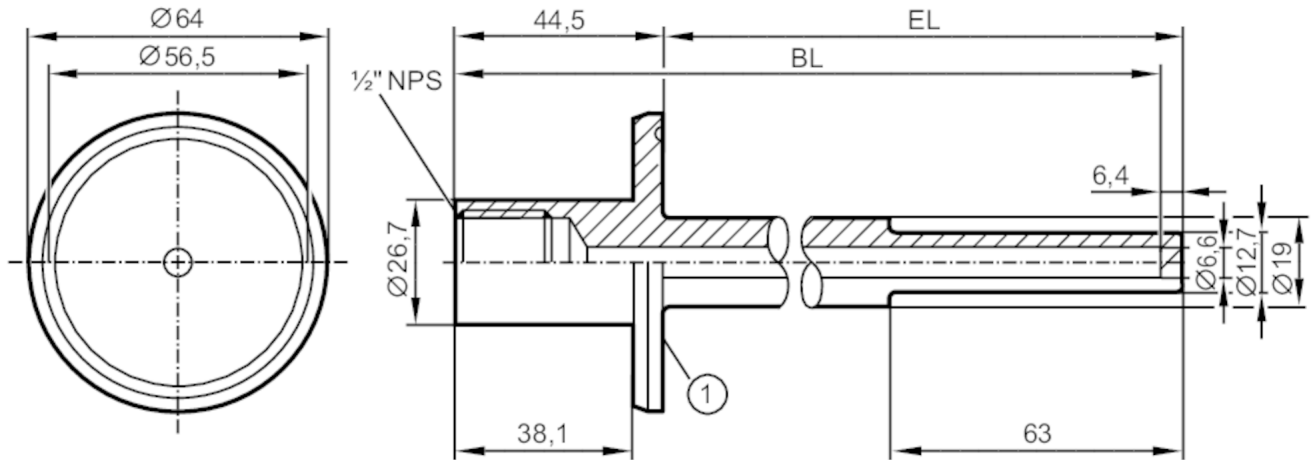

1 Clamp 2" ISO 2852



**EC 1935/2004 EHEDG Certified** 



## Application

|                       |                                     |
|-----------------------|-------------------------------------|
| Design                | for temperature sensors EL = 300 mm |
| Pressure rating [bar] | 25                                  |

## Mechanical data

|                                                   |      |                                                |
|---------------------------------------------------|------|------------------------------------------------|
| Weight                                            | [g]  | 545                                            |
| Materials                                         |      | stainless steel (316L/1.4404)                  |
| Sensor connection                                 |      | 1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT |
| Process connection                                |      | Clamp DN50 (2") DIN 32676 (ISO 2852)           |
| Surface characteristics Ra/Rz of the wetted parts |      | ≤ 0.6 / -                                      |
| Installation length EL                            | [mm] | 191                                            |
| Bore length BL                                    | [mm] | 228.6                                          |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|