




Flange plate for level sensors

FLANGE PLATE 54-52X52

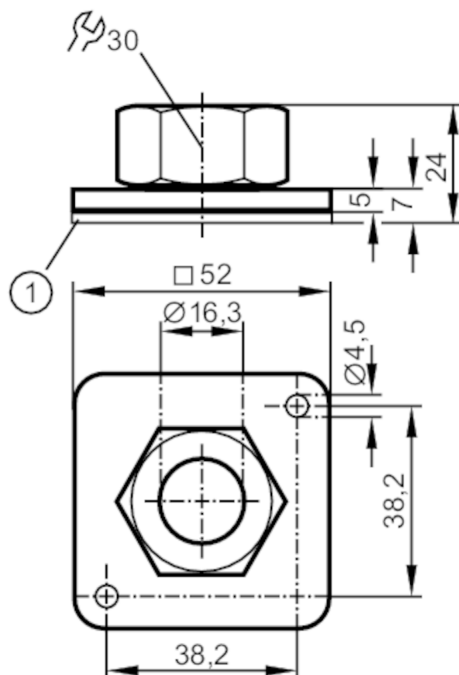

1 sealings

Application

Design	for capacitive level sensors LK, LI, LT, LL	
Pressure rating	[bar]	0.5

Operating conditions

Ambient temperature	[°C]	0...80
---------------------	------	--------

Mechanical data

Weight	[g]	121
Materials	flange: aluminium anodised; Lock nut: stainless steel; spacer: brass; clamping ring: FKM; Sealing: Tesnit	
Tightening torque	[Nm]	6...9
Sensor connection	clamp adapter Ø 16 mm	
Process connection	flange	

Remarks

Pack quantity	1 pcs.	
---------------	--------	--