


E43336



Coaxial pipe for level sensors

LR COAX TUBE G3/4 L800

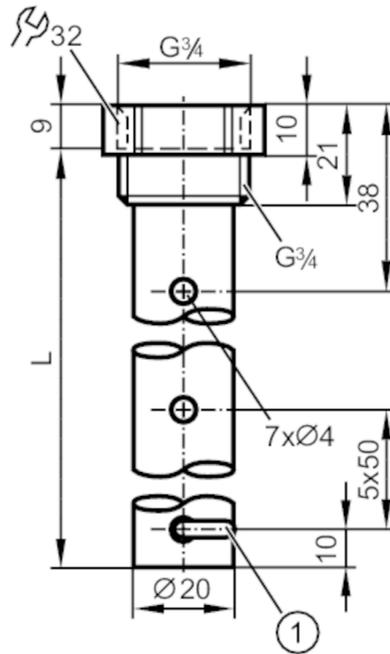

1 fixing bracket for centring piece

Application

Design	for level sensors LR	
Medium temperature	[°C]	-40...200
Pressure rating	[bar]	16
Vacuum resistance	[mbar]	-1000

Mechanical data

Weight	[g]	475
Materials	Coaxial pipe: stainless steel (304/1.4301); Sealing: NBR reinforced fibre; fixing bracket: stainless steel (301/1.4310); Centring piece: PPS reinforced fibre	
Sensor connection	threaded connection G 3/4 internal thread	
Process connection	threaded connection G 3/4 external thread	
Length L	[mm]	800

Accessories

Items supplied	Sealing: 1	
Accessories (optional)	Centring piece for coaxial pipes: 1, E43222	

Remarks

Remarks	When used under DNV GL conditions mounting of an additional centring piece is required	
Pack quantity	1 pcs.	