


# E43355



## Coaxial pipe for level sensors

LR COAX TUBE G3/4 L265

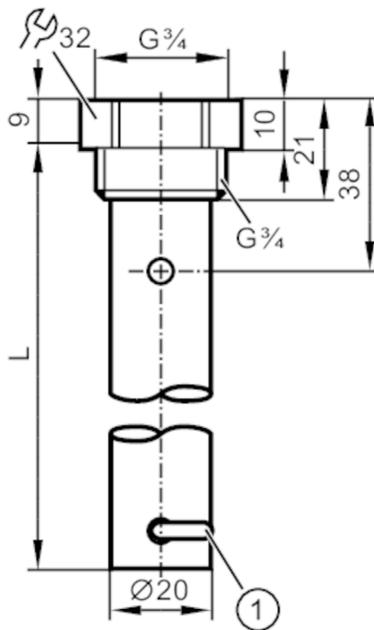

1 fixing bracket for centring piece

### CRN

| Application                                    |   |
|--|---|
| Design   | for level sensors LR  |
| Medium temperature [°C]                        | -40...200   |
| Pressure rating [bar]                          | 16  |
| Vacuum resistance [mbar]                       | -1000   |
| MAWP (for applications according to CRN) [bar] | 16  |
| Mechanical data                                |   |
| Weight [g]                                     | 194   |
| Materials                                      | Coaxial pipe: stainless steel (304/1.4301); Sealing: NBR reinforced fibre; fixing bracket: stainless steel (301/1.4310); Centring piece: PPS reinforced fibre |
| Sensor connection                              | threaded connection G 3/4 internal thread   |
| Process connection                             | threaded connection G 3/4 external thread   |
| Length L [mm]                                  | 265   |
| Accessories                                    |   |
| Items supplied                                 | Sealing: 1  |
| Remarks  |   |
| Pack quantity                                  | 1 pcs.  |