




AS-Interface automation set for pneumatic valve
actuators

Added Value package AS-i T5

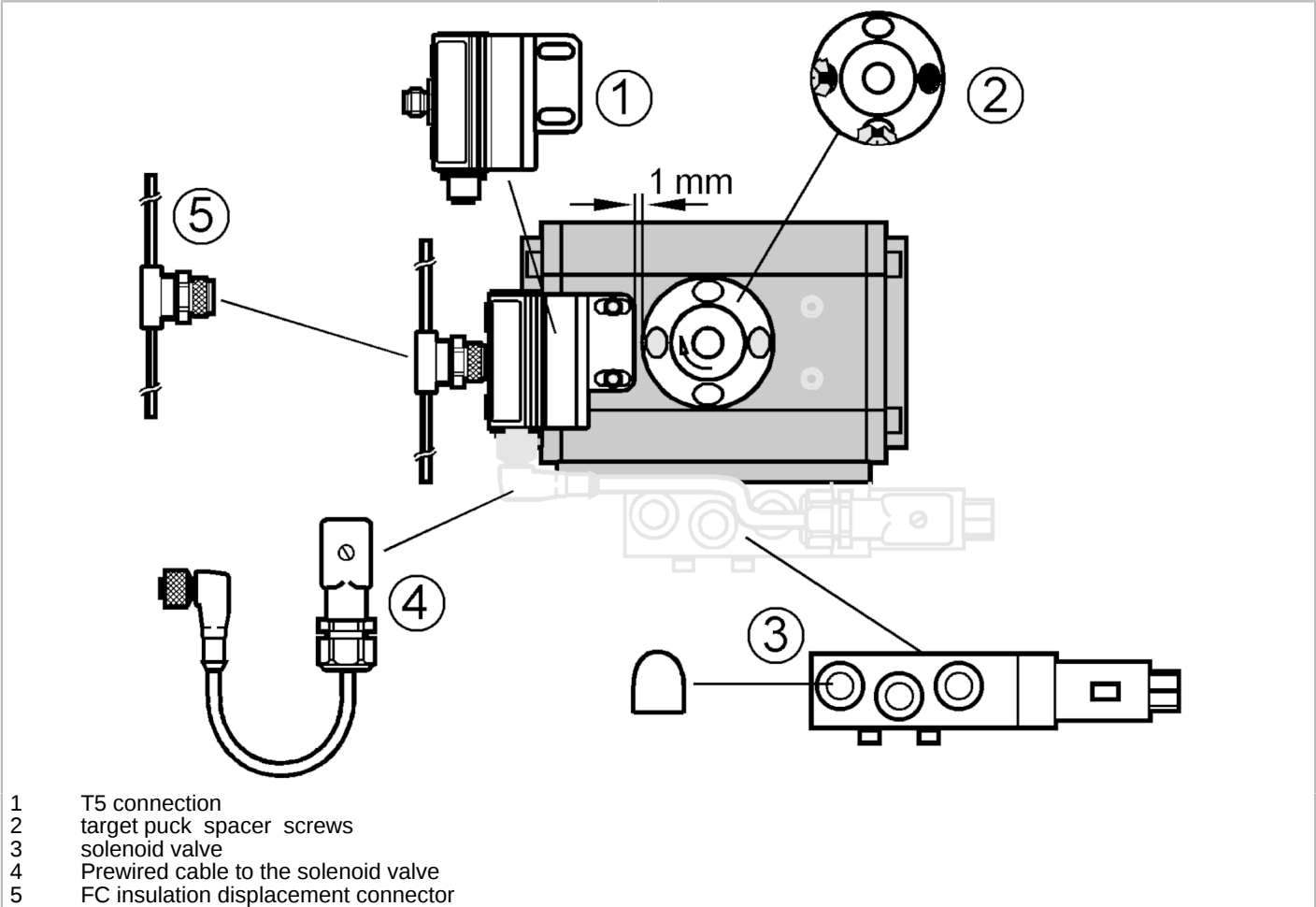

Product characteristics

Output function	PNP
Sensing range [mm]	4

Electrical data

Max. current consumption from AS-i [mA]	160
Operating voltage AUX DC [V]	26.5...31.6; ("supply class 2" to cULus)

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 1
------------------------------	---

Inputs

Number of digital inputs	2
--------------------------	---

Outputs

Number of digital outputs	1
Output function	PNP

Detection zone

Sensing range [mm]	4
--------------------	---

AS-i classification

AS-i version	2.1
AS-i profile	S-7.A.E
AS-i I/O configuration [hex]	7



AS-Interface automation set for pneumatic valve
actuators

Added Value package AS-i T5

AS-i ID code	[hex]	A.E
--------------	-------	-----

Mechanical data

Weight	[g]	900.95
Mounting		non-flush mountable
Hole spacing	[mm]	130
Shaft height of valve drive	[mm]	30

Accessories


Items supplied	dual sensor for actuator feedback: 1, AC2316
	Target pucks: 1, E17328
	solenoid valve: 1, Bürkert 428623
	silencer: 2, 780780N
	Flat cable insulation displacement connector: 1, E75471
	Connection cable: 1, E10845

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Electrical connection - plug

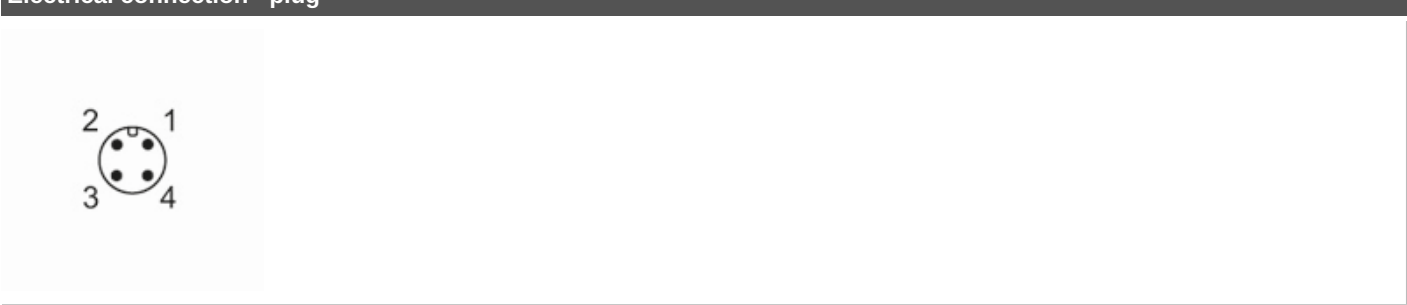


Connection

Connection

1	AS-i +
3	AS-i -

Electrical connection - socket

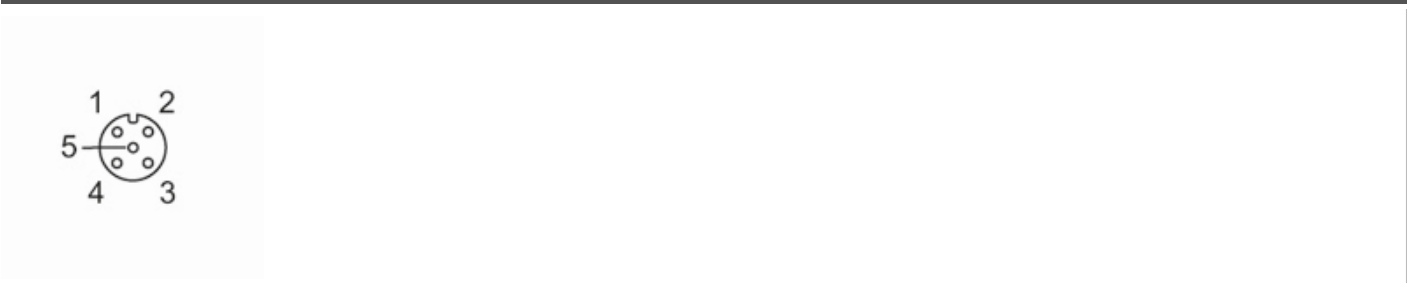

Outputs

3	external voltage -
4	switching output 1 +