




AS-Interface PCB module

AS-i pcb 2-DI/1-DO

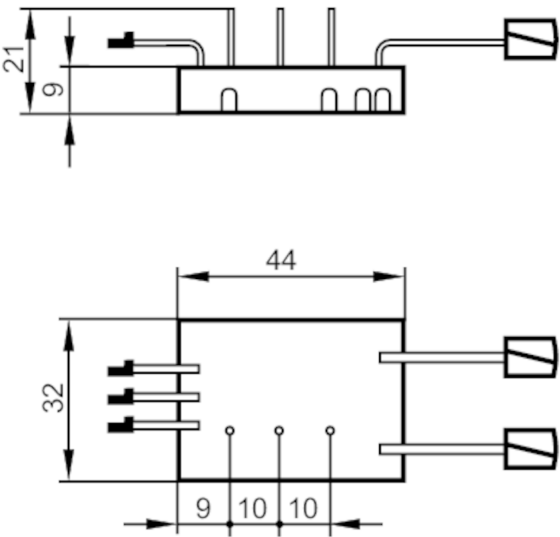

Application		
Application		housing for panel mounting
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 50
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Power supply	[V]	18...30; (DC)
Input current High	[mA]	> 5
Digital inputs protected against short circuits		no
Outputs		
Electrical design		PNP
Voltage range DC	[V]	DC
Max. current load per output	[mA]	10
Short-circuit proof		no
Actuator supply outputs		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...60



AS-Interface PCB module

AS-i pcb 2-DI/1-DO

Protection		IP 20; (depending on the housing)				
Tests / approvals						
EMC		EN 50295				
MTTF [years]		842				
AS-i classification						
AS-i version		2.11; 3.0				
Extended addressing mode		yes				
AS-i master profile		M2; M3; M4				
AS-i profile		S-7.A.E				
AS-i I/O configuration [hex]		7				
AS-i ID code [hex]		A.E				
AS-i certificate		75101				
Assignment of the data bits		data bit	D0	D1	D2	D3
		Designation	I-1 / O-1	I-2	-	-
Mechanical data						
Weight [g]		58.5				
Displays / operating elements						
Display		operation		LED, green		
		errors		LED, red		
		function		LED, yellow		
Remarks						
Pack quantity		1 pcs.				
Electrical connection						
Cable: 0.2 m						
AS-i +		brown				
AS-i -		blue				
I1		black				
I2		black				
O1		red				