


E11421



Jumper cable with valve plug

VVDAB031MSS00,3H03STGH030MSS

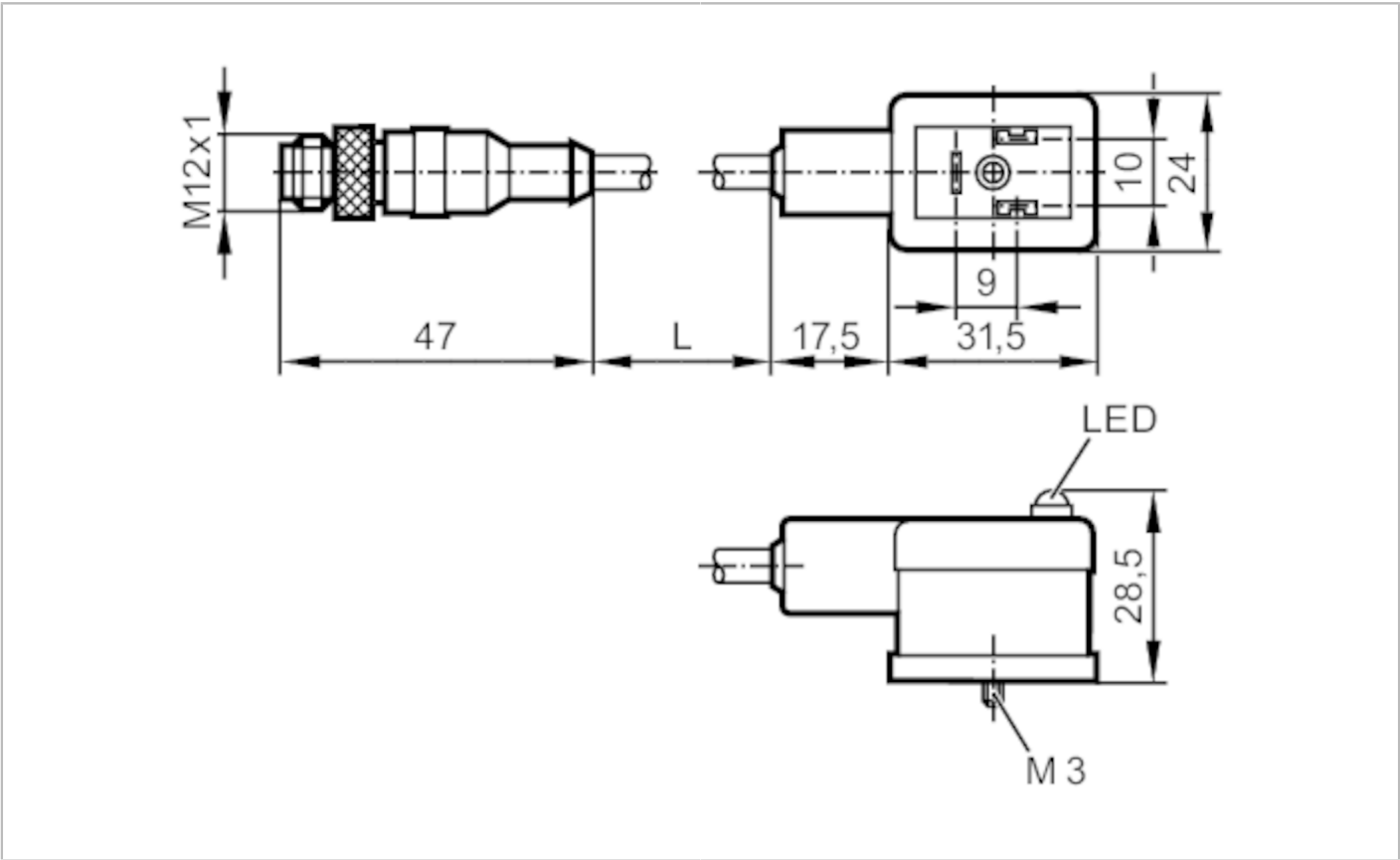

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)	
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection	IP 67	
Mechanical data		
Weight	[g]	58.2
Materials	PUR	
Moulded-body material	PUR	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	operation	1 x LED, yellow
Accessories		
Items supplied	screw	
	panel for labelling	

E11421



Jumper cable with valve plug

VVDAB031MSS00,3H03STGH030MSS

 
Remarks

Pack quantity

1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

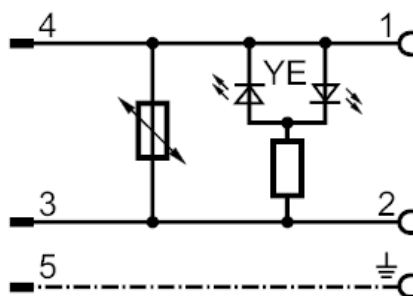

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

