

E11864




Wirable socket

SDOGH050VASFKPG

Article no longer available - archive entry

Alternative articles: EVF569

When selecting an alternative article and accessories please note that technical data may differ!

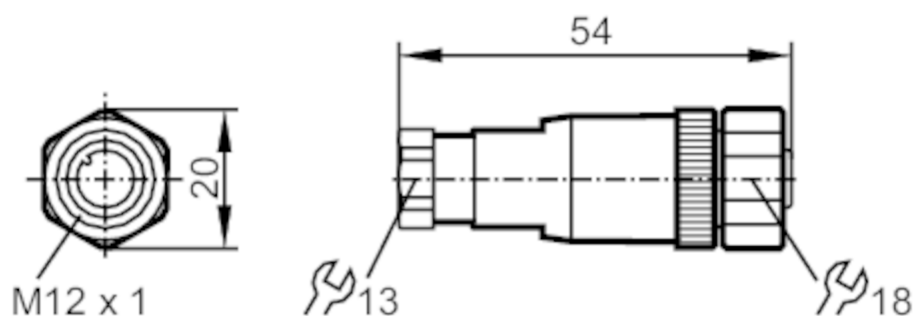

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	27.4
Dimensions	[mm]	20 x 20 x 54
Materials		PA
Moulded-body material		PA
Material nut		stainless steel

Remarks

Pack quantity	1 pcs.
---------------	--------

E11864



Wirable socket


SDOGH050VASFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

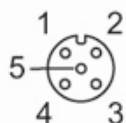

Connection

