


## Connection cable

CABLE CAN ADAPTER

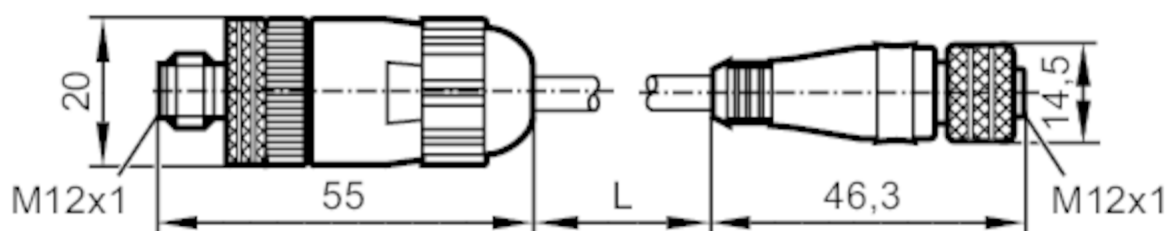

L: 0.15 m

## Application

|                 |                      |
|-----------------|----------------------|
| Special feature | Gold-plated contacts |
| Design          | CAN adapter cable    |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 30 AC / < 36 DC |
| Max. current load total | [A] | 4                 |

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -30...80 |
| Protection          |      | IP 68    |

## Mechanical data

|                       |      |                      |
|-----------------------|------|----------------------|
| Weight                | [g]  | 48.8                 |
| Dimensions            | [mm] | 20 x 20 x 55         |
| Materials             |      | PUR                  |
| Moulded-body material |      | PUR                  |
| Material nut          |      | brass, nickel-plated |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|



## Connection cable

CABLE CAN ADAPTER

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated



### Electrical connection

Cable: 0.15 m, PUR / PVC, black, Ø 6.8 mm; 4 x 0.25 mm<sup>2</sup>

### Connection

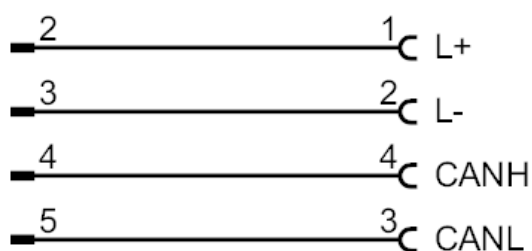

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

