


# E75228



## Push-in L-fitting for pneumatic connections

AirBox push-in L-connect 10pcs

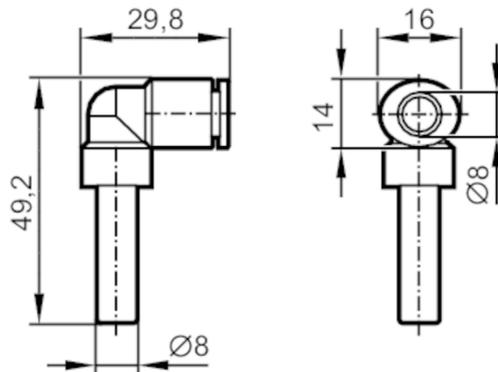

| Application              |  |
|--------------------------|--|
| Media                    | compressed air according to ISO 8573-1: 2001   |
| Operating conditions     |  |
| Operating pressure [bar] | 10; (min. -0,95)   |
| Ambient temperature [°C] | -20...80   |
| Mechanical data          |  |
| Weight [g]               | 69.5   |
| Materials                | housing: nickel-plated brass / PA66; release ring: polyoxymethylene;<br>Tooth lock washer: stainless steel; form ring: NBR |
| Tube fittings            | 8 mm   |
| Sleeve diameter [mm]     | 8  |
| Remarks                  |  |
| Pack quantity            | 10 pcs.  |