


Splitter box


ZDO8H050MSS0005H11

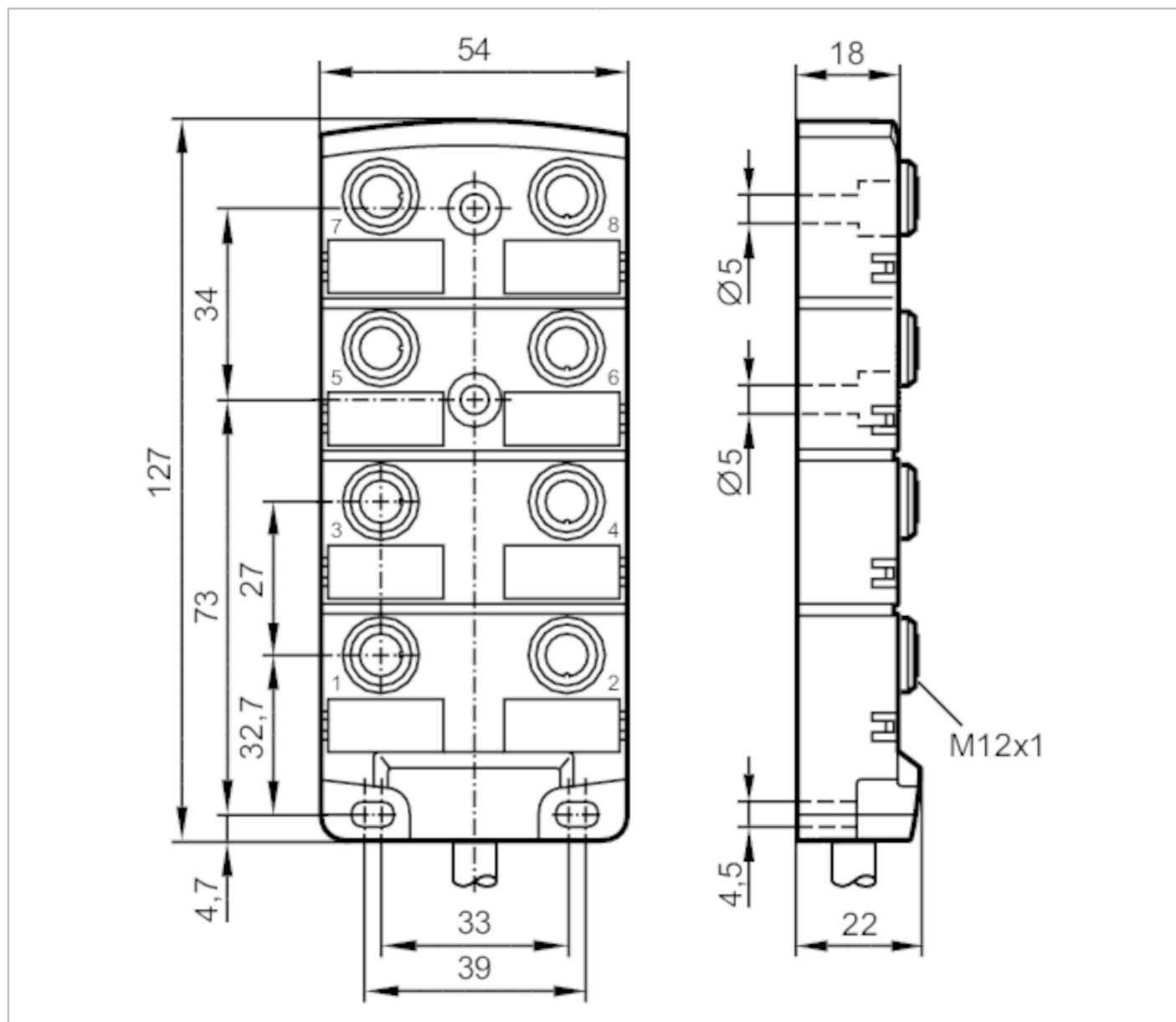

Application		
Special feature		Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 30 DC; ("supply class 2" to cULus)
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...80
Ambient temperature (moving)	[°C]	-5...60

**Splitter box**

ZDO8H050MSS0005H11

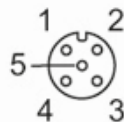Protection		IP 67; IP 68	
Tests / approvals			
UL approval		Enclosure type	Type 1
Mechanical data			
Weight		[g]	683.5
Dimensions		[mm]	22 x 54 x 127
Materials		PA	
Moulded-body material		PA	
Number of ports splitter box		8	
Connector type		M12	
Drag chain suitability		yes	
Drag chain suitability		bending radius for flexible use	min. 10 x cable diameter
		bending cycles	> 2 Mio.
Accessories			
Items supplied		Protective caps: 2	
		labels: 8	
Remarks			
Pack quantity		1 pcs.	
Electrical connection			
Cable: 5 m, PUR, Halogen-free, black, Ø 8.2 mm; 8 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 1 mm² (95 x Ø 0.1 mm)			
Electrical connection - slot			
Connector: 8 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm			
			



Splitter box

ZDO8H050MSS0005H11

Connection

BN	1 (1...8)	C
BU	3 (1...8)	C
GN/YE	5 (1...8)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C
PK	4 (5)	C
RD	4 (6)	C
BK	4 (7)	C
VT	4 (8)	C

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow