


DF3200



Distribution module for supply voltage

Pot.Module LOAD/2x5x 2.5mm²

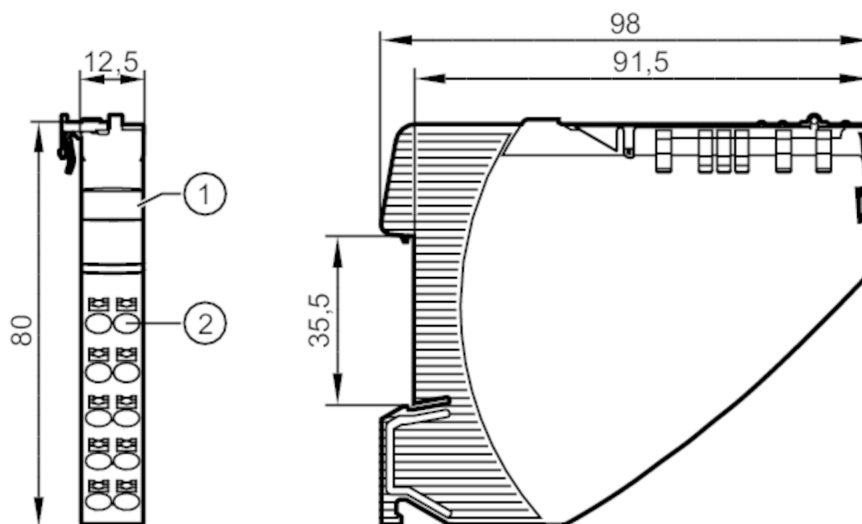

- 1 panel for labelling
- 2 push-in terminal 24 V DC



Application

Design potential module 2 x 5 x 2,5 mm²

Electrical data

Operating voltage [V]	18...30 DC
Nominal voltage DC [V]	24
Protection class	III
Max. load current [A]	20

Operating conditions

Ambient temperature [°C]	-25...60
Storage temperature [°C]	-40...70
Protection	IP 20

Tests / approvals

EMC	EN 61000-6-3	radiation of interference
	EN 61000-6-2	immunity

Mechanical data

Weight [g]	64.8
Type of mounting	mounting on DIN rail
Installation instruction	string mounting possible
Dimensions [mm]	80 x 12.5 x 98.5

DF3200



Distribution module for supply voltage

Pot.Module LOAD/2x5x 2.5mm²

Electrical connection

push-in terminals:

Connection

