




G1 ASEPTOFLEX VARIO leak test

LEAKTEST G1 ASEPTOFLEX VARIO

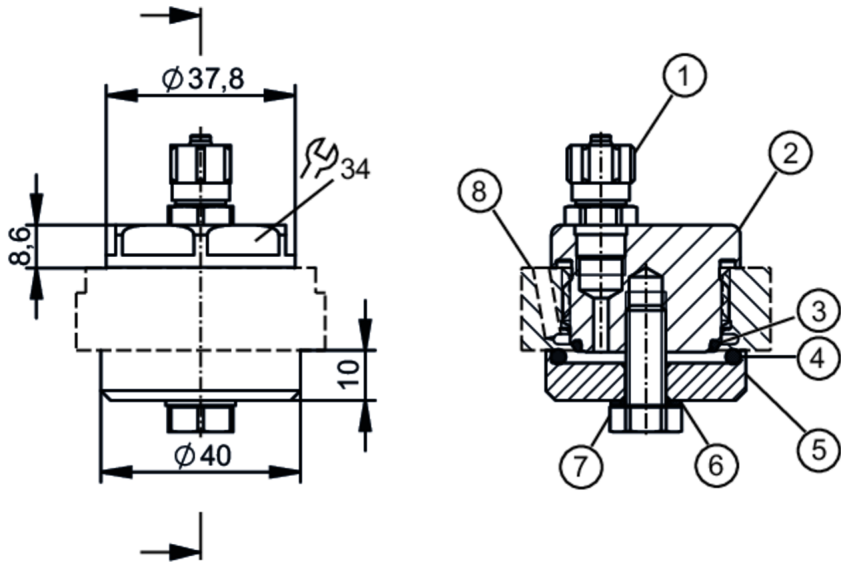

- 1 quick connector CK-1/8-PK-4 (2027)
- 2 end cap G1
- 3 O-ring 24.0x2.0 EPDM
- 4 O-ring 32.0x3.0 NBR
- 5 seal washer G1
- 6 Gasket stainless steel (303/1.4305) / NBR
- 7 hexagonal head screw DIN EN ISO 4017 - M8x20
- 8 Adapter not supplied

| Application           |                                                             |
|-----------------------|-------------------------------------------------------------|
| Design                | leak test for Aseptoflex Vario welding adapters             |
| Application           | leak test after welding and, if necessary, grinding process |
| Pressure rating [bar] | 10                                                          |
| Mechanical data       |                                                             |
| Weight [g]            | 290.4                                                       |
| Materials             | stainless steel (303/1.4305); Al; EPDM; NBR                 |
| Process connection    | G 1 Aseptoflex Vario                                        |
| Remarks               |                                                             |
| Pack quantity         | 1 pcs.                                                      |