




RFID tag

ID-TAG/R40X10/04

Article no longer available - archive entry

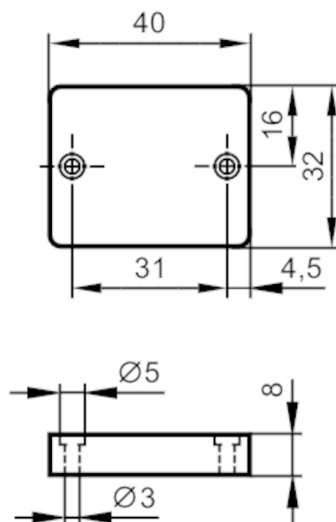

Application

Operating temperature (active)	[°C]	-20...65
Peak temperature (passive)	[°C]	180

Electrical data

Operating frequency	[MHz]	865...870
Memory size	[bit]	96
Max. read cycles		unlimited
Max. write cycles		100000

Operating conditions

Ambient temperature	[°C]	-20...65
Storage temperature	[°C]	-40...180

Mechanical data

Weight	[g]	18.5
Dimensions	[mm]	32 x 8 x 40
Materials		PA 6.6 black

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E80354



RFID tag

ID-TAG/R40X10/04

Other data

read distance (m)	
DTE80x	0.7
DTE90x	-
ANT860 / ANT960	-
ANT820 / ANT920	-