




M22 light

KTE-VOKM--RKG/US/IO

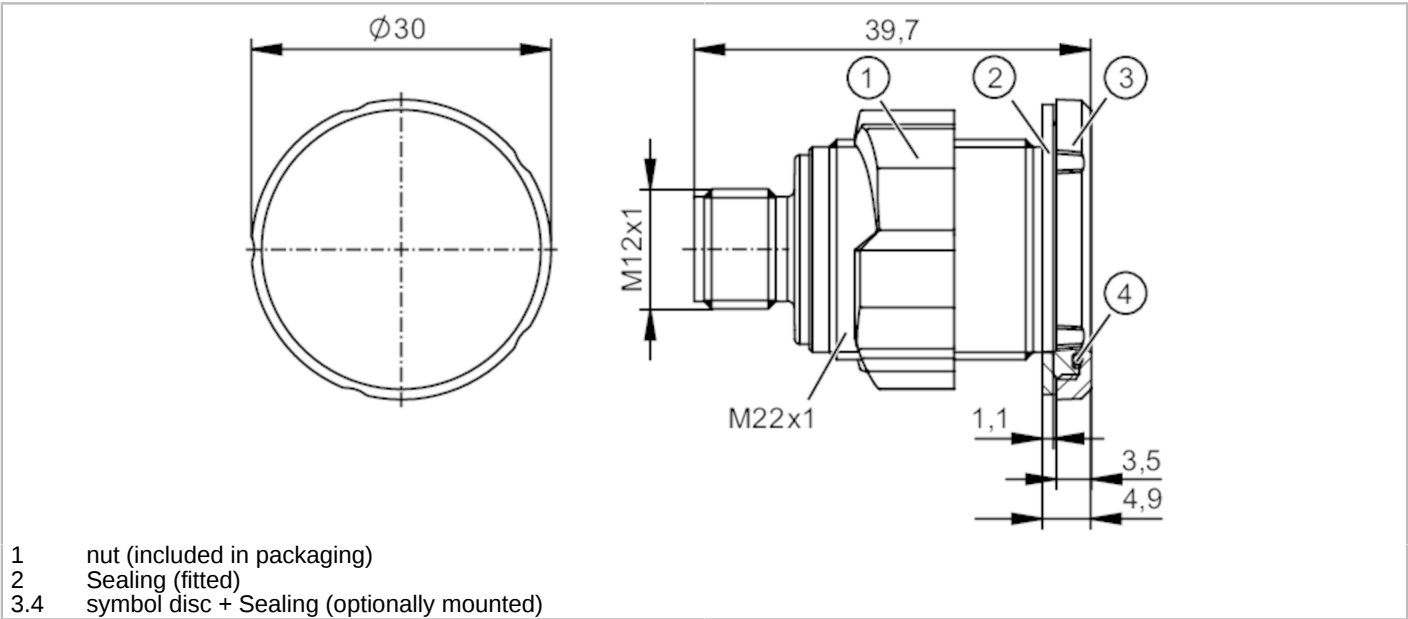

Product characteristics	
Communication interface	IO-Link
Housing	threaded type
Dimensions [mm]	M22 x 1 / L = 39.7
Electrical data	
Operating voltage [V]	8...32 DC
Protection class	III
Reverse polarity protection	yes
Current consumption	< 7,2 mA; (LED off: Ub = 24V)
	< 125 mA; (LED white, max. brightness: Ub = 8V)
	< 79 mA; (LED white, max. brightness: Ub = 12V)
	< 43 mA; (LED white, max. brightness: Ub = 24V)
	< 35 mA; (LED white, max. brightness : Ub = 32V)
Inputs	
Total number of inputs	2
Switching level high [V]	< 4.8; (at 24V safely off : Voltage <= Ub*0,2)
Switching level low [V]	> 19.2; (at 24V safely on : Voltage >= Ub*0,8)
Inputs	according to the standard IEC 61131-2 (Typ 3)
Interfaces	
Communication interface	IO-Link
Transmission type	COM2 (38,4 kBaud)
IO-Link revision	1.1.3



M22 light

KTE-VOKM--RKG/US/IO

Profiles		Function class	Designation
		0x0002	Fixed Switching Sensor
		0x4000	Identification and Diagnosis
		0x8101	Locator
		0x8102	ProductURI
		0x800C	Sensor Control
Min. process cycle time	[ms]	5	
Operating conditions			
Ambient temperature	[°C]	-30...65	
Protection		IP 65; IP 67; IP 69K; (on the front)	
Tests / approvals			
EMC		EN 61000-4-2 ESD	4 kV CD / 8 kV AD
		EN 61000-4-3 HF radiated	10 V/m / 3 V/m
		EN 61000-4-4 Burst	2 kV
		EN 61000-4-6 HF conducted	10 V
		IEC 61000-6-3, EN 55011	(Class B)
		IEC 61000-4-5 Surge	1 kV (L+ to L- , 42 Ω, 0,5 μF) / 0,5 kV (all cables to L- , 42 Ω, 0,5 μF)
Vibration resistance		EN 60068-2-6 Fc	20 g (10...3000 Hz) / 50 sweep cycles, 1 octave per minute, in 3 axes
Shock resistance		EN 60068-2-27 Ea	50 g 11 ms half-sine; 20 shocks each in every direction of the 3 coordinate axes
Continuous shock resistance		EN 60068-2-29 Eb	40 g 6 ms half-sine; 8000 shocks each in every direction of the 3 coordinate axes
MTTF	[years]	309	
Mechanical data			
Weight	[g]	48.1	
Housing		threaded type	
Dimensions	[mm]	M22 x 1 / L = 39.7	
Thread designation		M22 x 1	
Materials		housing: PA; lock nut: PBT	
Displays / operating elements			
Display		operation	LED, RGB configurable
Accessories			
Items supplied		lock nuts: 1	
Accessory required		symbol disc	
		O-ring	
Remarks			
Pack quantity		1 pcs.	

M22 light

KTE-VOKM--RKG/US/IO

Electrical connection

Connector: 1 x M12; coding: A



Connection

