


E3M132



Female cordset

POWER SUPPLY CABLE O3M ILLUMINATION 5M

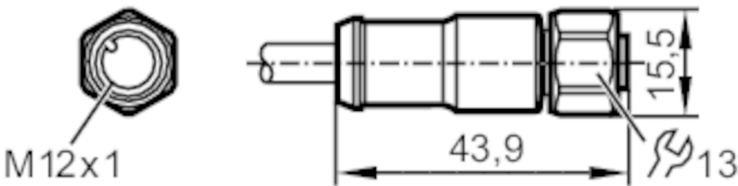

Application		
System	gold-plated contacts; Drag chain suitability	
Electrical data		
Operating voltage	[V]	< 25 AC / < 60 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 68
Mechanical data		
Weight	[g]	309.7
Dimensions	[mm]	15.5 x 15.5 x 43.9
Material		PUR
Molded-body material		PUR
Material nut		diecast zinc
Drag chain suitability		yes
Drag chain suitability	Bending radius for fixed installation	≥ 30 mm
Remarks		
Pack quantity	1 pcs.	

E3M132



Female cordset


POWER SUPPLY CABLE O3M ILLUMINATION 5M

Electrical connection

Cable: 5 m, PUR, black, Ø 6 mm; 4 x 0.75 mm²

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated

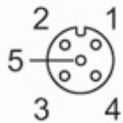

Connection

