


# E11807



## Female cordset

ADOGH080MSS0005H08

For 8-wire cordsets the core colors are not standardized.  
Please note the wiring of the sensor and the cordsets (see data sheet).

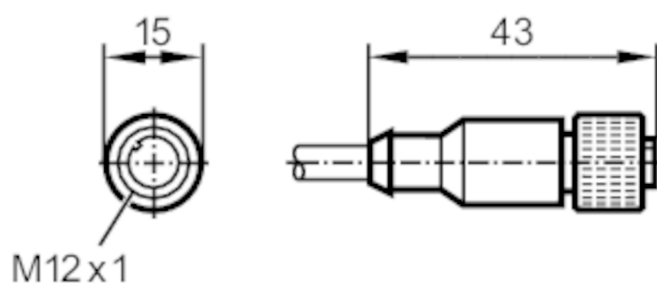

### Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
-------------------	-----	-------------------

### Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 68

### Mechanical data

Weight	[g]	313.7
Dimensions	[mm]	15 x 15 x 43
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E11807



## Female cordset


ADOGH080MSS0005H08

### Electrical connection

Cable: 5 m, PUR, black, Ø 6.2 mm; 8 x 0.25 mm²

### Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

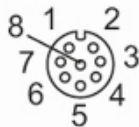

### Connection

1	BN
2	WH
3	BU
4	BK
5	GY
6	PK
7	VT
8	OG

Colors to DIN EN  
60947-5-2

	Core colors :
BK =	black
BN =	brown
BU =	blue
GY =	grey
PK =	pink
OG =	orange
VT =	lilac
WH =	white