


E11311



Female cordset

ADOGH080MSS0010H08

For 8-wire cordsets the core colors are not standardized.
Please note the wiring of the sensor and the cordsets (see data sheet).

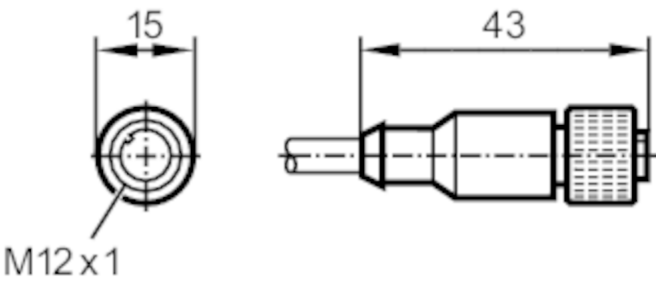

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 68
Mechanical data		
Weight	[g]	618.1
Dimensions	[mm]	15 x 15 x 43
Material		PUR
Molded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11311



Female cordset


ADOGH080MSS0010H08

Electrical connection

Cable: 10 m, PUR, black, Ø 6.2 mm; 8 x 0.25 mm²

Electrical connection - Socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

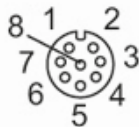

Connection

1	BN
2	WH
3	BU
4	BK
5	GY
6	PK
7	VT
8	OG

Colors to DIN EN
60947-5-2

Core colors :

BK =	black
BN =	brown
BU =	blue
GY =	grey
PK =	pink
OG =	orange
VT =	lilac
WH =	white