


AS-Interface illuminated pushbutton module

Moduloberteil aktiv,

Article no longer available - archive entry

Alternative articles: AC2018

When selecting an alternative article and accessories please note that technical data may differ!

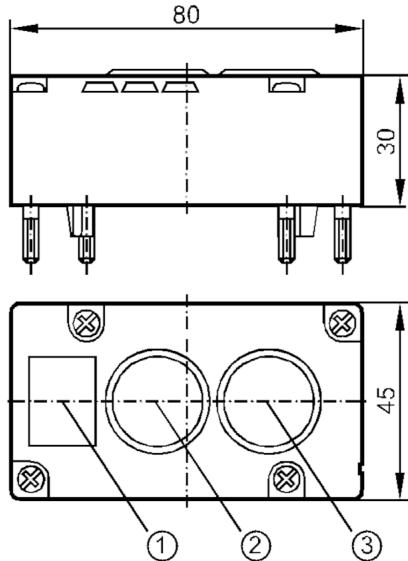

- 1 panel for labelling
2 pushbutton / LED green
3 pushbutton / LED red

CE

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 55

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature	[°C]	-25...60
Protection		IP 67

Tests / approvals

EMC	EN 50295	
-----	----------	--

AS-i classification

AS-i profile	S-3.F
--------------	-------

AS-i I/O configuration	[hex]	3
------------------------	-------	---

AS-i ID code	[hex]	F
--------------	-------	---

Assignment of the data bits	data bit	D0	D1	D2	D3
	pushbutton	2	1	-	-
	LED	-	-	2	1

AC2010



AS-Interface illuminated pushbutton module

Moduloberteil aktiv,

Mechanical data

Type of mounting	AS-i interface to FC and SC lower parts
Materials	PBT

Remarks

Remarks	The pushbuttons (EAO type 84) provide protection against accidental contact. Housing and pushbuttons can be labelled.
Pack quantity	1 pcs.

Electrical connection

contact pins to module lower part, FK / PG:
