


E3M133



Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 10M

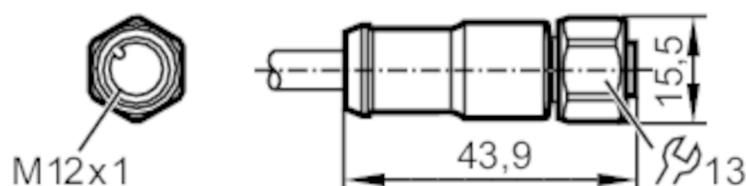

Application

Special feature	Gold-plated contacts; Drag chain suitability
-----------------	--

Electrical data

Operating voltage	[V]	< 25 AC / < 60 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 68

Mechanical data

Weight	[g]	595
Dimensions	[mm]	15.5 x 15.5 x 43.9
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc
Drag chain suitability		yes
Drag chain suitability	bending radius for fixed installation	≥ 30 mm

Remarks

Pack quantity	1 pcs.
---------------	--------

E3M133



Connecting cable with socket


POWER SUPPLY CABLE O3M ILLUMINATION 10M

Electrical connection

Cable: 10 m, PUR, black, Ø 6 mm; 4 x 0.75 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated

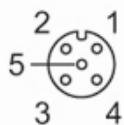

Connection

