


## Connecting cable with socket

ADOGF030ZDS0010A03

Article no longer available - archive entry

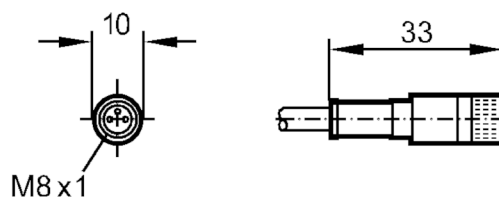

## Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | < 60 AC/DC |
|-------------------|-----|------------|

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 68    |

## Mechanical data

|                       |      |              |
|-----------------------|------|--------------|
| Dimensions            | [mm] | 10 x 10 x 33 |
| Materials             |      | PUR          |
| Moulded-body material |      | PUR          |
| Material nut          |      | diecast zinc |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

## Electrical connection

Cable: 10 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (128 x Ø 0.05 mm )

## Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc



# E10712



## Connecting cable with socket

ADOGF030ZDS0010A03

### Connection



|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |