

E10724




Connecting cable with socket

ADOGH040VAS0005A04

Article no longer available - archive entry

Alternative articles: EVC002

When selecting an alternative article and accessories please note that technical data may differ!

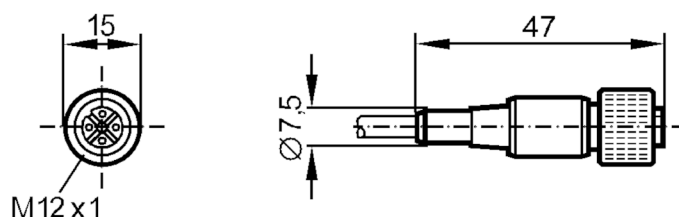

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 47
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel (303/1.4305)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10724



Connecting cable with socket

ADOGH040VAS0005A04

Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: stainless steel (303/1.4305)



Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white