


E10824



Jumper cable with valve plug

VSTAH050VAN00,6E02VSAB030--N

Article no longer available - archive entry

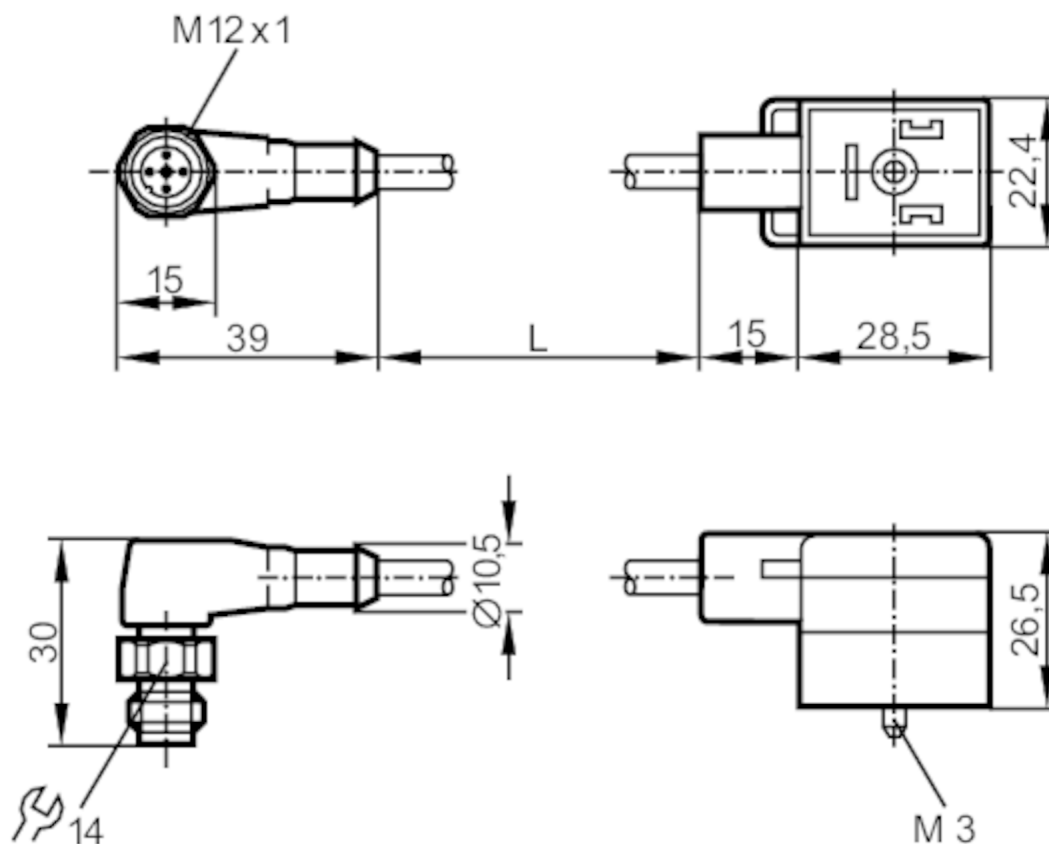

Application

Application NAMUR

Electrical data

Operating voltage [V] < 15 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 30 x 15 x 39

Materials TPU; PUR

Moulded-body material TPU / PUR

Material nut stainless steel (316L/1.4404)

Accessories

Items supplied screw
panel for labelling

Remarks

Pack quantity 1 pcs.

E10824



Jumper cable with valve plug

VSTAH050VAN00,6E02VSAB030--N

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (316L/1.4404)



Electrical connection

Cable: 0.6 m, PVC, blue, Ø 5 mm; 2 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (316L/1.4404)

