

E10830




Connecting cable with socket

ADOAF030MSS0005A03

Article no longer available - archive entry

Alternative articles: E11490

When selecting an alternative article and accessories please note that technical data may differ!

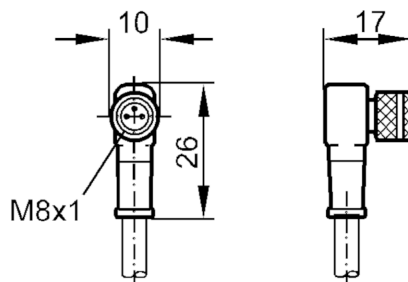

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	17 x 10 x 26
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10830



Connecting cable with socket

ADOAF030MSS0005A03

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue