


E10838



Connecting cable with plug

ASTAH050VAS00,6A03

Article no longer available - archive entry

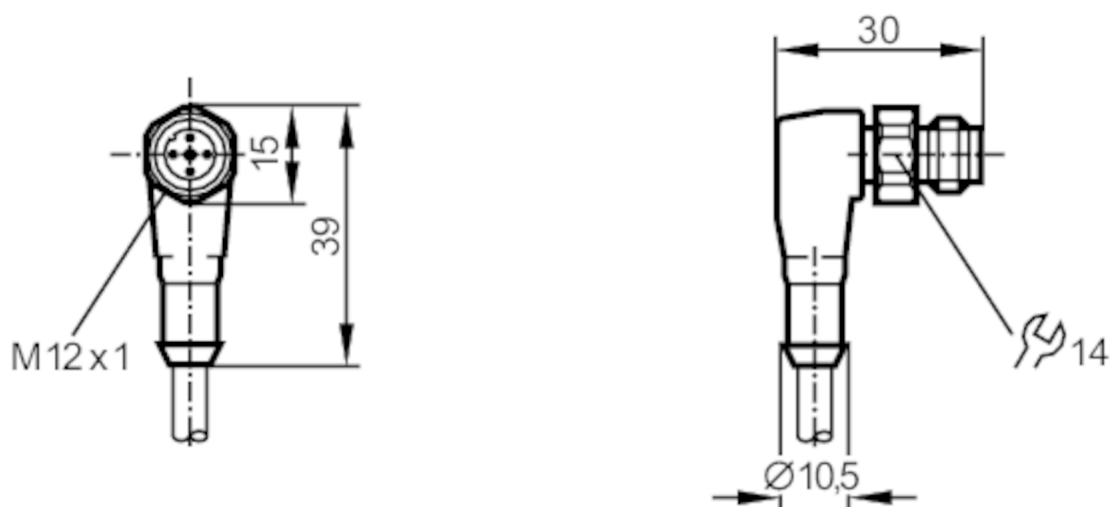

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 24 AC/DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

39 x 30 x 15

Materials

PUR; TPU

Moulded-body material

PUR / TPU

Material nut

stainless steel (316L/1.4404)

Remarks

Pack quantity

1 pcs.

E10838



Connecting cable with plug


ASTAH050VAS00,6A03

Electrical connection


Cable: 0.6 m, PUR, Halogen-free, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PUR / TPU; Locking: stainless steel (316L/1.4404); Tightening torque: 0.5 Nm

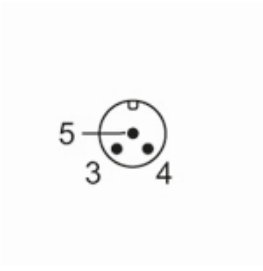

Connection

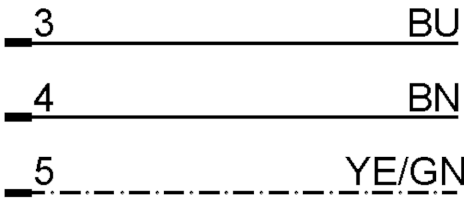

BN = Core colours :
BU = brown
GN/YE = blue
green/yellow