


Connecting cable with socket

ADOAH042ZDS0005E03

Article no longer available - archive entry

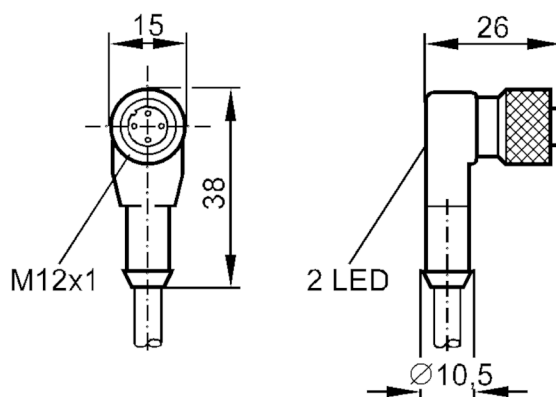

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	diecast zinc, nickel-plated
--------------	-----------------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10257



Connecting cable with socket

ADOAH042ZDS0005E03

Electrical connection

Cable: 5 m, PVC, black, Ø 4.5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated



Connection



BN = Core colours : brown
BK = black
BU = blue