


## Splitter box

ZDO6H050MSS0010H07

Article no longer available - archive entry

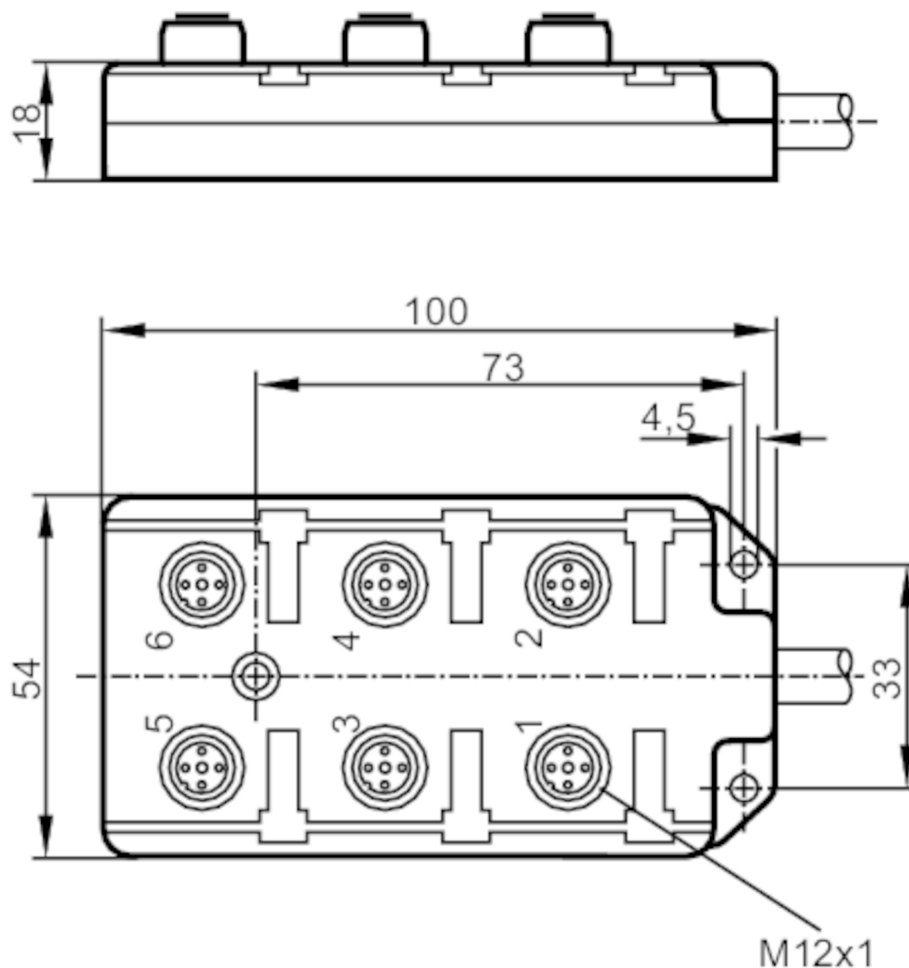

### Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes                                                    |

### Electrical data

|                                   |     |                   |
|-----------------------------------|-----|-------------------|
| Operating voltage                 | [V] | < 60 AC / < 75 DC |
| Protection class                  |     | II                |
| Max. current load per module/slot | [A] | 4                 |
| Max. current load total           | [A] | 12                |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -15...80 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |     |
|-----------------------|-----|
| Materials             | TPU |
| Moulded-body material | TPU |

# E11721



## Splitter box

ZDO6H050MSS0010H07

|                              |     |
|------------------------------|-----|
| Number of ports splitter box | 6   |
| Connector type               | M12 |

### Remarks


|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm<sup>2</sup> (43 x Ø 0.1 mm ) + 3 x 0.75 mm<sup>2</sup> (95 x Ø 0.1 mm )

### Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

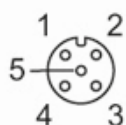

### Connection

|       |           |
|-------|-----------|
| BN    | 1 (1...6) |
| BU    | 3 (1...6) |
| GN/YE | 5 (1...6) |
| WH    | 4 (1)     |
| GN    | 4 (2)     |
| YE    | 4 (3)     |
| GY    | 4 (4)     |
| PK    | 4 (5)     |
| RD    | 4 (6)     |

|      |                |
|------|----------------|
|      | Core colours : |
| BN = | brown          |
| BU = | blue           |
| GN = | green          |
| GY = | grey           |
| PK = | pink           |
| RD = | red            |
| WH = | white          |
| YE = | yellow         |