


E11795



Wirable socket

SDOAA030MSSFKPG

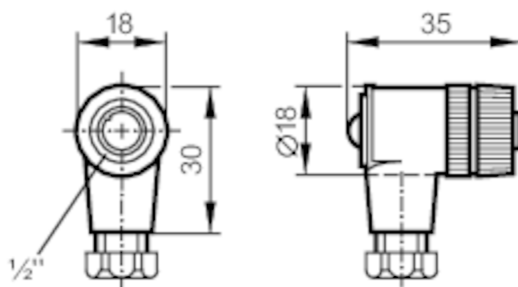

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	24.8
Dimensions	[mm]	35 x 20 x 30
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11795



Wirable socket

SDOAA030MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

