

E11221





Connecting cable with socket

ADOAF040VAS0010E04

Article no longer available - archive entry

Alternative articles: EVT140

When selecting an alternative article and accessories please note that technical data may differ!

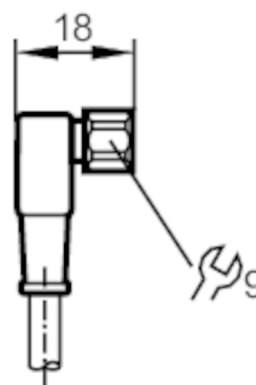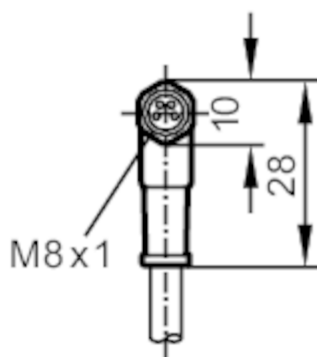

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (316L/1.4404)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11221



Connecting cable with socket

ADOAF040VAS0010E04

 
Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Tightening torque: 0.6...0.7 Nm



Connection

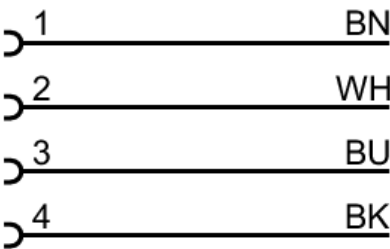

Core colours :
BK = black
BN = brown
BU = blue
WH = white