

E11229




Connection cable

VDOGH080MSS0003H08STGH080MSS

Article no longer available - archive entry

Alternative articles: E11230
When selecting an alternative article and accessories please note that technical data may differ!

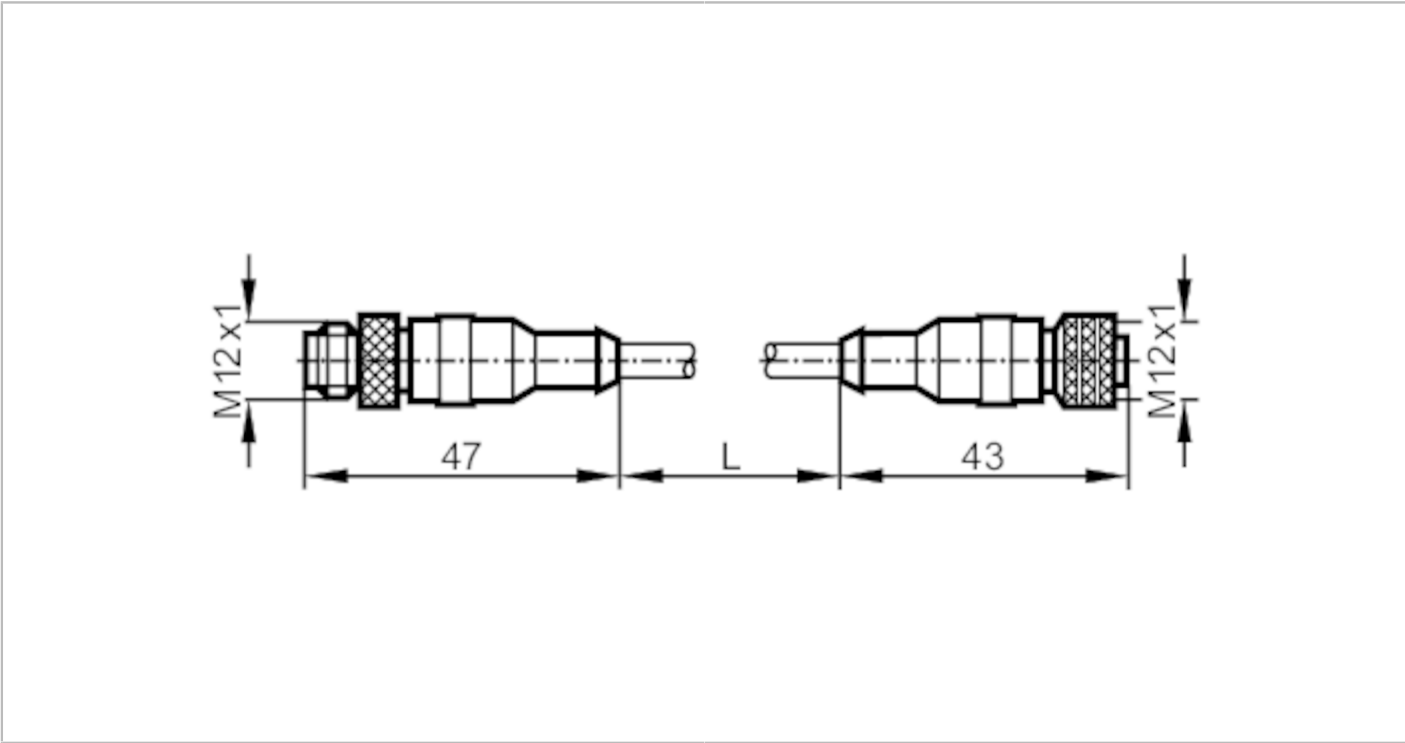

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage [V]	< 30 AC / < 36 DC
Operating conditions	
Ambient temperature [°C]	-25...80
Protection	IP 68
Mechanical data	
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.




Connection cable

VDOGH080MSS0003H08STGH080MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

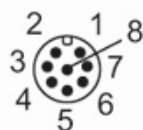

Electrical connection

Cable: 3 m, PUR, Halogen-free, black, Ø 6.8 mm; 8 x 0.25 mm²

Connection

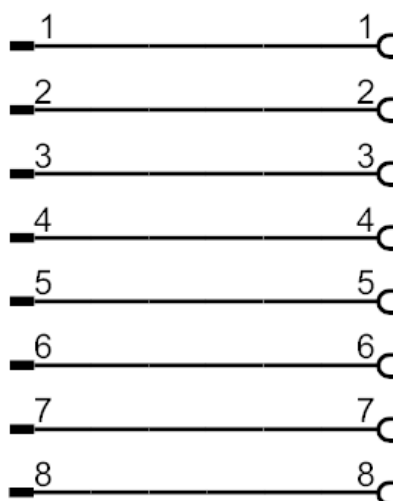

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm

