


# E12648



## Connecting cable with socket

ADOAX050MSS0010H05

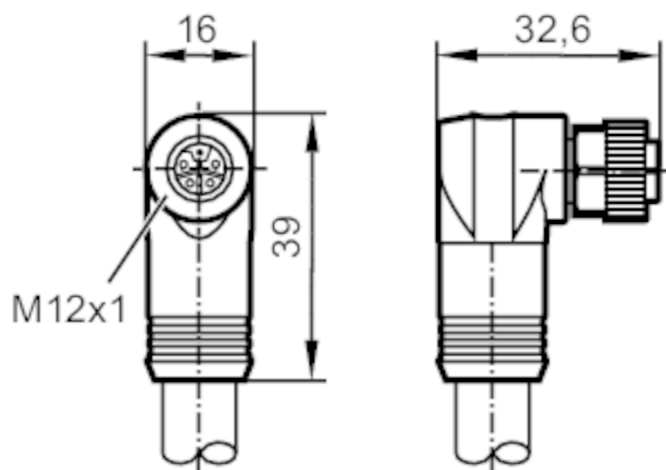

| Application             |      |                      |
|-------------------------|------|----------------------|
| Special feature         |      | Gold-plated contacts |
| Design                  |      | power cable, L-coded |
| Electrical data         |      |                      |
| Operating voltage       | [V]  | 63 DC                |
| Max. current load total | [A]  | 16                   |
| Operating conditions    |      |                      |
| Ambient temperature     | [°C] | -40...90             |
| Protection              |      | IP 67                |
| Mechanical data         |      |                      |
| Weight                  | [g]  | 2163                 |
| Dimensions              | [mm] | 39 x 16 x 38.1       |
| Materials               |      | PP                   |
| Moulded-body material   |      | TPE                  |
| Material nut            |      | brass, nickel-plated |
| Remarks                 |      |                      |
| Pack quantity           |      | 1 pcs.               |

# E12648



## Connecting cable with socket

ADOAX050MSS0010H05

### Electrical connection

Cable: 10 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm²

### Electrical connection - socket

Connector: 1 x M12, angled; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |
| 5 | GY |