


E18107



Connection cable

VSTGH050VAS00.4E03VDAA030--S

Article no longer available - archive entry

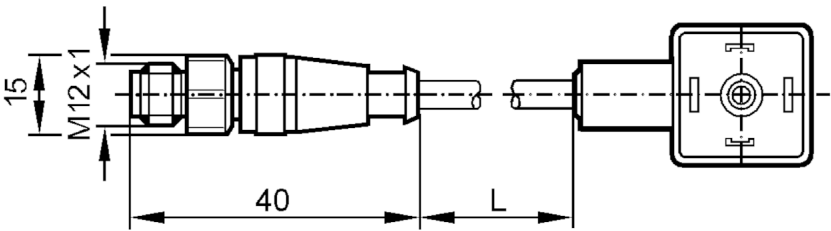

Application		
Special feature		Gold-plated contacts
Electrical data		
Frequency AC	[Hz]	47...63
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	54.431
Materials		TPE
Moulded-body material		TPE
Material nut		stainless steel (316Ti/1.4571)
Remarks		
Pack quantity		1 pcs.



Connection cable

VSTGH050VAS00.4E03VDAA030--S

Electrical connection

Cable: 0.4 m, PVC, grey; 3 x 0.34 mm² / AWG 22


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Electrical connection

Connection

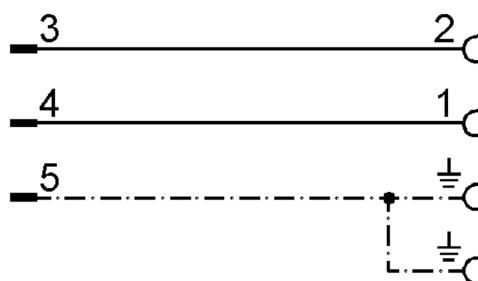

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

