





Connecting cable with socket

ADOGH140MSS0005A11

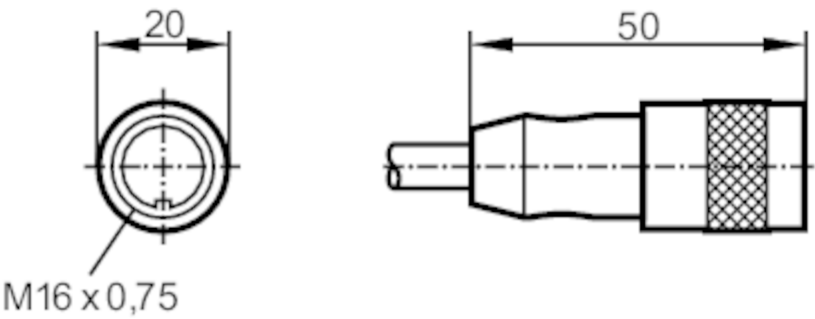

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Weight	[g]	635.029
Dimensions	[mm]	20 x 20 x 50
Materials		PUR black
Moulded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR, black, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)		
Electrical connection - socket		

Connector: 1 x M16, straight; Moulded body: PUR; Locking: brass, nickel-plated

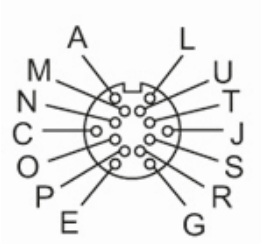


E18147



Connecting cable with socket

ADOGH140MSS0005A11

Connection

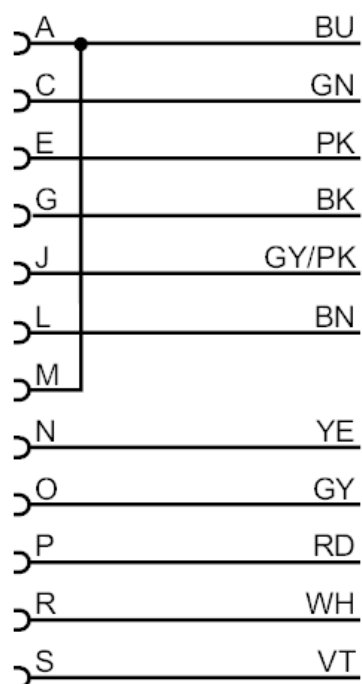

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow