


E20430



Connecting cable with socket

ADOGB030MSS0002E03

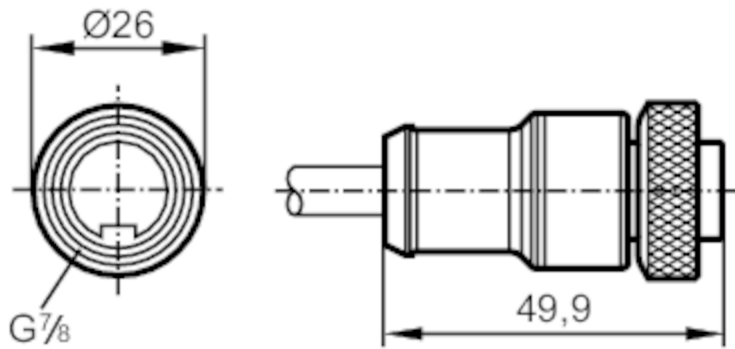

Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-30...80
Ambient temperature (moving)	[°C]	-5...80
Protection		IP 68
Mechanical data		
Weight	[g]	117.5
Dimensions	[mm]	26 x 26 x 49.9
Moulded-body material		TPU
Material nut		diecast zinc
Remarks		
Pack quantity		1 pcs.

E20430



Connecting cable with socket

AD0GB030MSS0002E03

Electrical connection


Cable: 2 m, PVC, black, Ø 5.4 mm; 3 x 0.5 mm²

Electrical connection - socket

Connector: 1 x 7/8", straight; Moulded body: TPU; Locking: diecast zinc



Connection

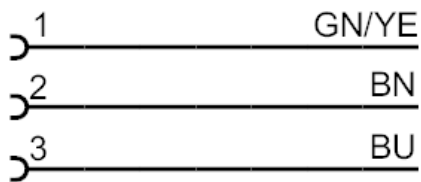

BN =	Core colours :
BU =	brown
GN/YE =	blue
	green/yellow