

E30086




Process adapter Varivent

ADAPT IFM-VARIV D=68 O-RG

phase-out article

Alternative articles: E33222 or E33229

When selecting an alternative article and accessories please note that technical data may differ!

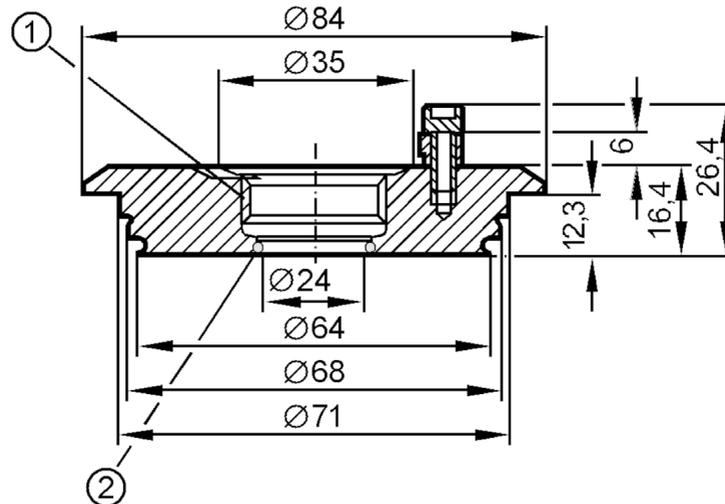

- 1 Aseptoflex thread
- 2 sealings

Application

Installation	with O-ring
Pressure rating [bar]	25

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]	490
Type of mounting	with O-ring
Materials	stainless steel (316L/1.4404); O-ring: EPDM
Sensor connection	Aseptoflex
Process connection	Varivent Form N, DN40...DN150 (1,5...6"), Ø 68 mm
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4

Accessories

Accessories (optional)	O-rings: 5, EPDM, E30054 O-rings: 5, FPM (Viton), E30053
------------------------	-------------------------------------------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------