

# E33021



## Process adapter Varivent


ADAP IFM-VARIV D=50(DN25/1)

Article no longer available - archive entry

Alternative articles: E33721

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

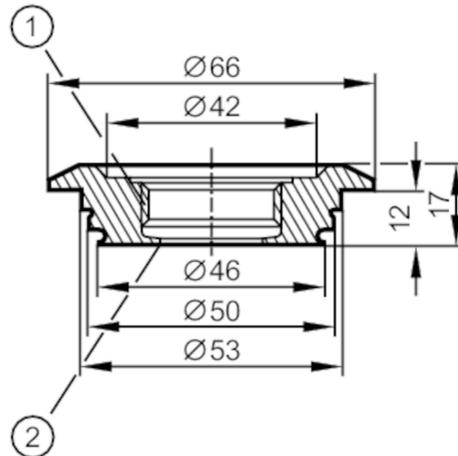

- 1 Aseptoflex thread
- 2 Aseptoflex sealing edge

EC 1935/2004 EHEDG Certified 

### Application

Pressure rating [bar] 25

### Tests / approvals

Pressure Equipment Directive A possible classification to PED depends on the application and has to be carried out by the user / operator.

Safety instructions The compatibility between medium and product material has to be checked in all applications.

### Mechanical data

Weight [g] 241.8

Materials stainless steel (316L/1.4404)

Sensor connection Aseptoflex

Process connection Varivent Form F, DN25 (1"), Ø 50 mm

Surface characteristics Ra/Rz of the wetted parts 0.4 / 4

Hygienic equipment class to DIN 11866 H4

### Remarks

Pack quantity 1 pcs.