


E43344



Process adapter for SMS pipe fitting

ADAPT G1/2 - SMS DN50/2"

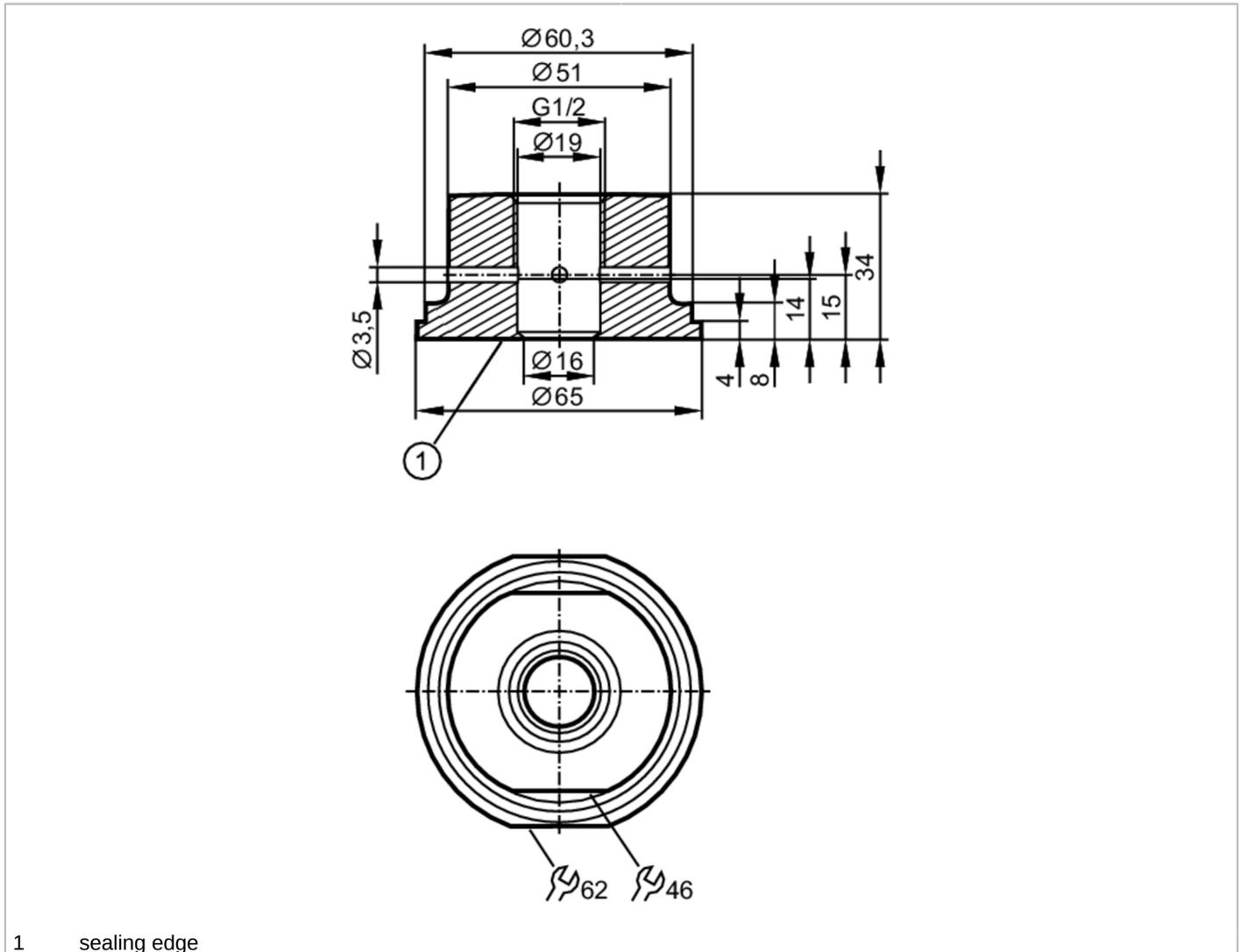

EC 1935/2004 FCM FDA

Application	
Design	with leakage port
Pressure rating [bar]	16
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	570.5
Materials	stainless steel (316L/1.4435)
Sensor connection	G 1/2 sealing cone
Process connection	SMS pipe fitting DN50 (2")
Surface characteristics Ra/Rz of the wetted parts	< 0.8 / 8
Sealing	metal to PEEK

E43344



Process adapter for SMS pipe fitting

ADAPT G1/2 - SMS DN50/2"

Hygienic equipment class to
DIN 11866

H3

Remarks

Pack quantity

1 pcs.