




AS-Interface flat cable insulation displacement
connector

FC Quick Connect M12

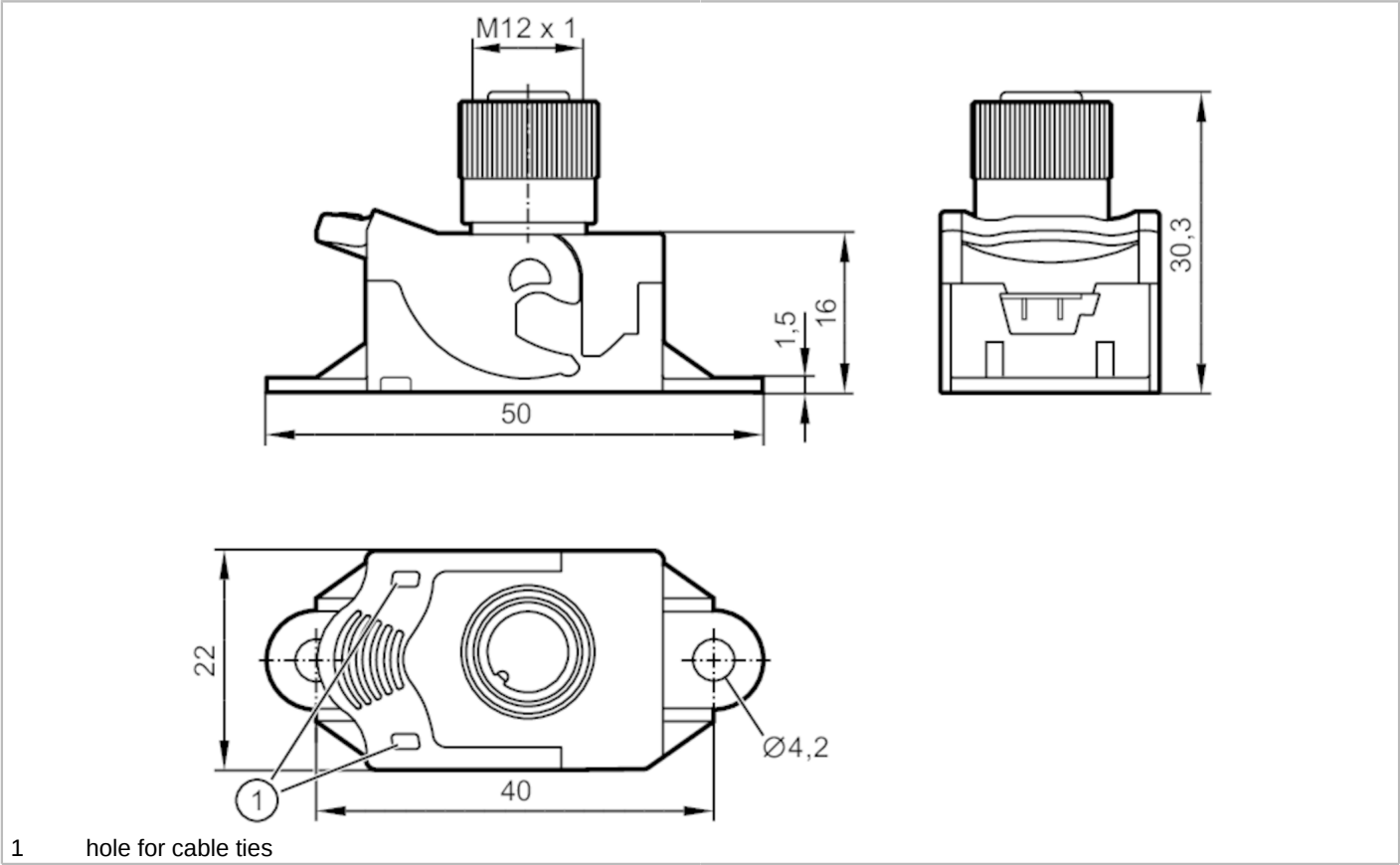

Electrical data		
Operating voltage	[V]	< 42 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...70
Storage temperature	[°C]	-25...75
Protection		IP 67
Tests / approvals		
UL approval	power supply	Class 2
Mechanical data		
Weight	[g]	17.7
Materials	housing: PA; O-ring: FKM; Lock nut: brass nickel-plated; contact pins: bronze tin-plated	
Remarks		
Remarks	The flat cable must not end in the device.	
Pack quantity	1 pcs.	




AS-Interface flat cable insulation displacement
connector

FC Quick Connect M12

Electrical connection

Connector: M12; coding: A; Tightening torque: 0.4...0.6 Nm

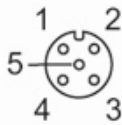

	when connected to yellow AS-i flat cable
1	AS-i +
2	n.c.
3	AS-i -
4	n.c.
5	n.c.
	when connected to black flat cable
1	AUX +
2	n.c.
3	AUX -
4	n.c.
5	n.c.