


# KI5083



## Capacitive sensor

KI-3200NFPKGP2T/US

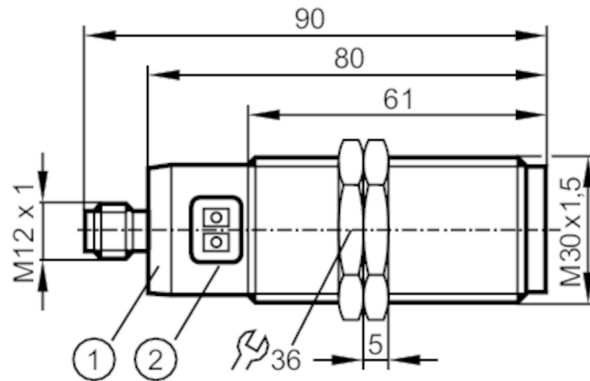

- 1 LED ring  
2 programming buttons



### Product characteristics

Electrical design	PNP
Output function	normally open / normally closed; (selectable)
Sensing range [mm]	20
Communication interface	IO-Link
Housing	threaded type
Dimensions [mm]	M30 x 1.5 / L = 90

### Electrical data

Operating voltage [V]	10...36 DC
Current consumption [mA]	< 20
Protection class	II
Reverse polarity protection	yes
Measuring principle	capacitive

### Outputs

Electrical design	PNP
Output function	normally open / normally closed; (selectable)
Max. voltage drop switching output DC [V]	2.5
Permanent current rating of switching output DC [mA]	200
Switching frequency DC [Hz]	10
Short-circuit proof	yes
Overload protection	yes

### Detection zone

Sensing range [mm]	20
--------------------	----

### Accuracy / deviations

Hysteresis [% of Sr]	1...15
----------------------	--------

# KI5083



## Capacitive sensor

KI-3200NFPKGP2T/US

Switch point drift	[% of Sr]	-20...20
<b>Interfaces</b>		
Communication interface		IO-Link
Transmission type		COM1 (4,8 kBaud)
IO-Link revision		1.1
SDCI standard		IEC 61131-9 CDV
Profiles		Smart Sensor
SIO mode		yes
Min. process cycle time	[ms]	101
Supported DeviceIDs	Type of operation	DeviceID
	Default	388
<b>Operating conditions</b>		
Ambient temperature	[°C]	-25...80
Note on ambient temperature		temperature of the sensing face: -25...110 °C
Protection		IP 65; IP 67
<b>Tests / approvals</b>		
EMC	EN 61000-4-2 ESD	8 kV AD
	EN 61000-4-3 HF radiated	10 V/m
	EN 61000-4-4 Burst	2 kV
	EN 61000-4-6 HF conducted	3 V
	EN 55011	class B
Vibration resistance	EN 60068-2-6 Fc	(10...55 Hz) / 1 mm amplitude, oscillation period 5 min., 30 min. per axis at resonance or 55 Hz
Shock resistance	EN 60068-2-27 Ea	30 g 6 shocks / 11 ms half-sine (x, y, z)
MTTF	[years]	663
<b>Mechanical data</b>		
Weight	[g]	88
Housing		threaded type
Mounting		non-flush mountable
Dimensions	[mm]	M30 x 1.5 / L = 90
Thread designation		M30 x 1.5
Materials		housing: PBT; pushbuttons: TPE-U; LED window: PC
<b>Displays / operating elements</b>		
Display	switching status	1 x LED, yellow
Teach function		yes
Electronic lock		yes
<b>Accessories</b>		
Items supplied		lock nuts: 2
<b>Remarks</b>		
Pack quantity		1 pcs.

# KI5083



## Capacitive sensor


KI-3200NFPKGP2T/US

### Electrical connection - plug

Connector: 1 x M12; coding: A



### Connection

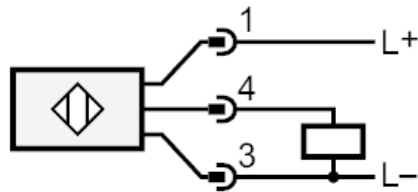

4: OUT / IO-Link