

AC3225




AS-Interface repeater

SmartL25 AS-i Repeater II

discontinued article

Alternative article: AC3226 When selecting an alternative article and accessories please note that technical data may differ! –
When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2019

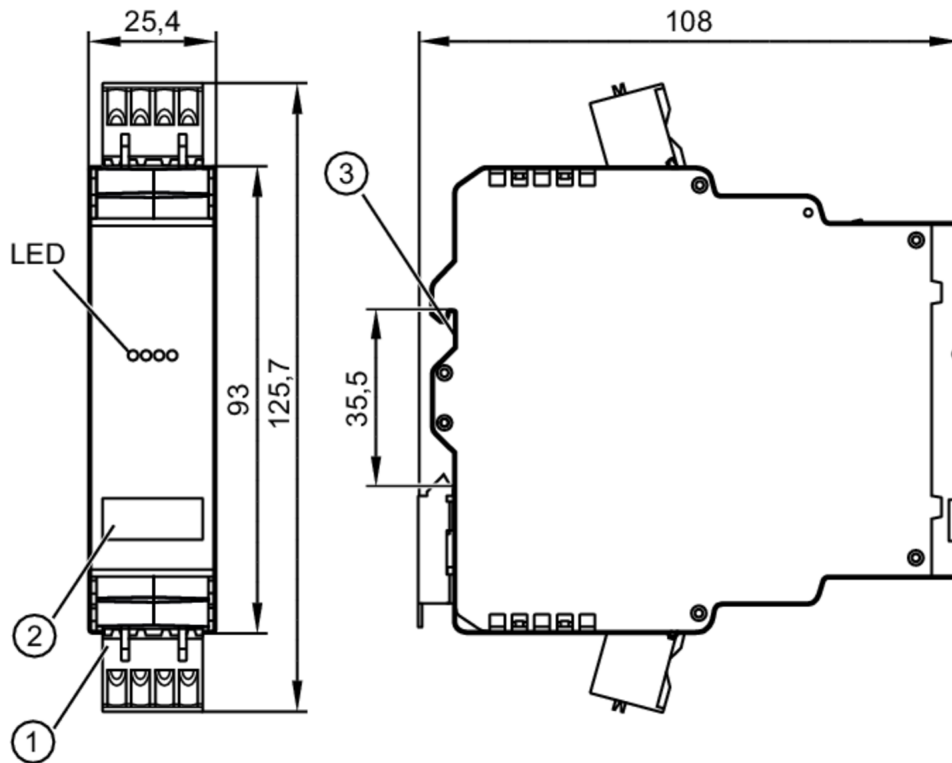

- 1 plug with cage clamp connection
- 2 panel for labelling
- 3 mounting on DIN rail



Application	
Application	extension of the AS-i network by another 100 m
Electrical data	
Nominal voltage DC [V]	26.5...31.6
Max. current consumption from AS-i [mA]	60; (per AS-i line)
Undervoltage monitoring	no
Outputs	
Electrical design	AS-i
Electrically separated	yes
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 20
Tests / approvals	
EMC	EN 62026-2



AS-Interface repeater

SmartL25 AS-i Repeater II

AS-i classification		
AS-i certificate pending	yes	
Mechanical data		
Weight [g]	154	
Housing	mounting on DIN rail	
Materials	PC-GF20	
Displays / operating elements		
Display	operation	2x LED, green
	short circuit	2x LED, red
Accessories		
Accessories (supplied)	COMBICON connectors	
Remarks		
Remarks	The AS-i extender takes no slave address.	
	The total number of slaves per master string remains unchanged.	
	No parameter setting necessary.	
Pack quantity	1 pcs.	
Electrical connection		
	outgoing AS-i cable	
A-	AS-i - line 2	
A+	AS-i + line 2	
A-	AS-i - line 2	
A+	AS-i + line 2	
	incoming AS-i cable	
A+	AS-i + line 1	
A-	AS-i - line 1	
A+	AS-i + line 1	
A-	AS-i - line 1	

discontinued article

Alternative article: AC3226 When selecting an alternative article and accessories please note that technical data may differ! –
When selecting an alternative article and accessories please note that technical data may differ! – Discontinuation date: 31.03.2019