




Fibre optic through-beam sensor

FE-00-P-V-E1/0,1m

Article no longer available - archive entry

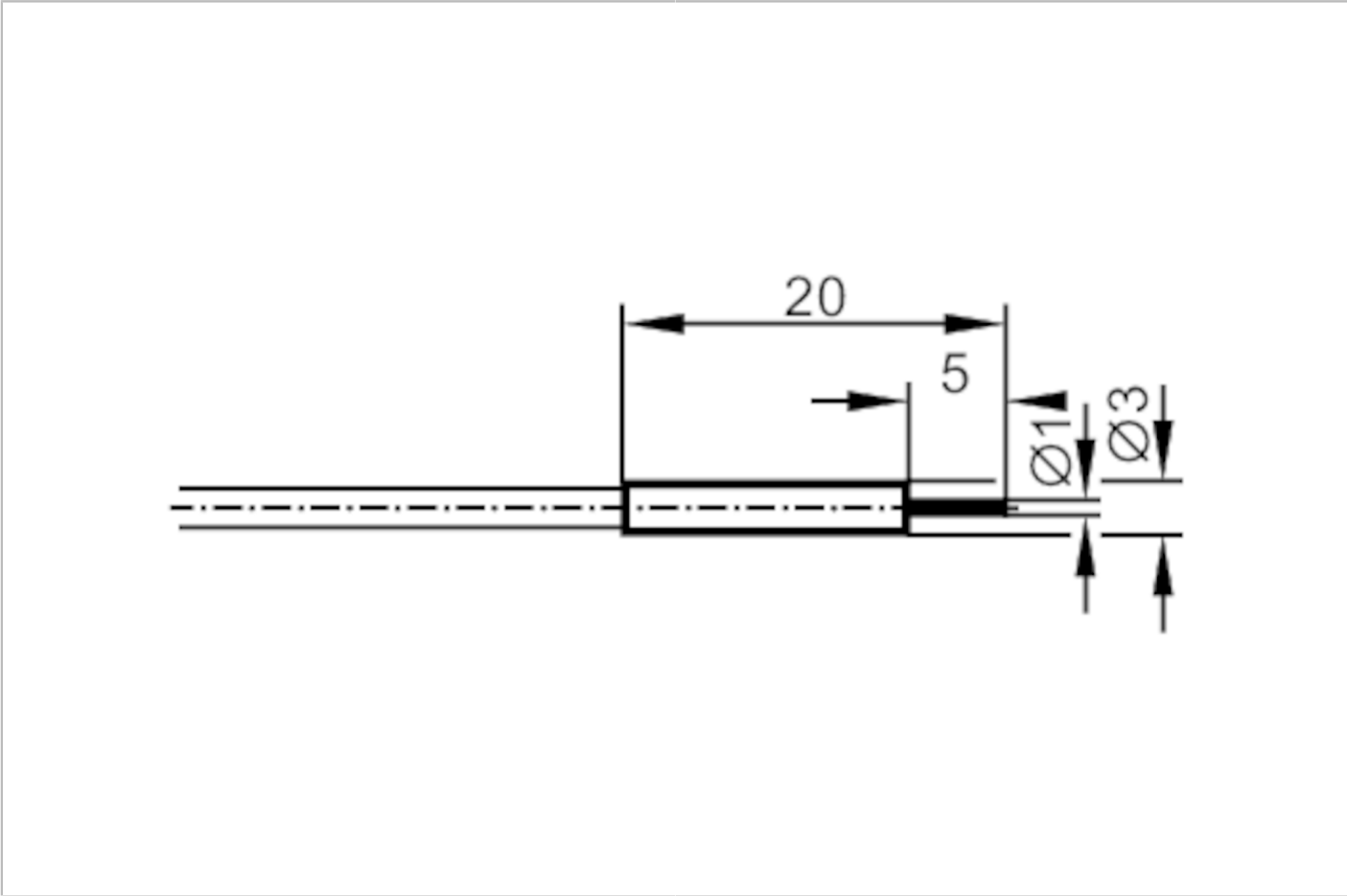

Application		
Function principle		Through-beam sensor
Detection zone		
Range with fibre-optic amplifier type		OKF; OUF
OKF		
Range of fibre optics	[mm]	50
OUF		
Range of fibre optics	[mm]	50
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	1
Sensing head length	[mm]	5
Total length	[mm]	100
Min. bending radius	[mm]	10
Materials		Adapter: PPE
Fibre material		glass

E20089



Fibre optic through-beam sensor

FE-00-P-V-E1/0,1m

Fibre head material	stainless steel (303/1.4305)
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.