




Fibre optic diffuse reflection sensor

FT-00-P-A-E3/2M

Article no longer available - archive entry

Alternative articles: E20350

When selecting an alternative article and accessories please note that technical data may differ!

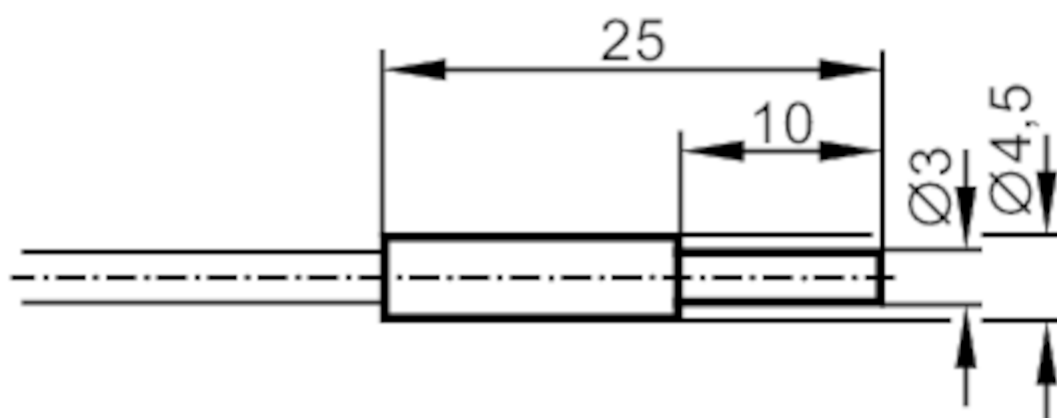

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

32

OUF

Range fibre optics

[mm]

32

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

25

Total length

[mm]

2000

E20144



Fibre optic diffuse reflection sensor

FT-00-P-A-E3/2M

Min. bending radius	[mm]	20
Materials		Adapter: PPE
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		PVC
Remarks		
Pack quantity		1 pcs.