

ZDO6H059MSS0000-00STAM190MSS

Artículos alternativos: EBC008

Technical drawing of the LED module showing top and side views with dimensions.

Top View Dimensions:

- Overall width: 125
- Distance between LED columns: 107
- Distance from LED columns to the right edge: 4,5
- Overall height: 60
- Distance from the top edge to the LED array: 18
- Distance from the bottom edge to the LED array: 28

Side View Dimensions:

- Overall height: 39
- Mounting holes: M23x1

Component Labels:

- LED
- M12x1

Característica especial	Libre de siliconas; Contactos dorados
Libre de siliconas	sí

Tensión de alimentación	[V]	10...30 DC
Clase de protección		II
Corriente máxima por módulo / punto de conexión	[A]	4
Corriente máxima total	[A]	10

Temperatura ambiente	[°C]	-15...80
Grado de protección		IP 67

E10946



Caja repartidora


ZDO6H059MSS0000-00STAM190MSS

Datos mecánicos		
Dimensiones	[mm]	28 x 60 x 125
Materiales		TPU
Material del cuerpo		TPU
Número de puntos de conexión en el repartidor central		6
Tipo de conector		M12
Indicaciones / elementos de mando		
Indicación	Estado de conmutación	12 x LED, amarillo
	Disponibilidad	1 x LED, verde
Notas		
Cantidad por pack		1 unid.
Conexión eléctrica - Conexión		
Conector: 1 x M23; cuerpo: TPU; Contactos: dorado; Par de apriete: 0,5 Nm		

Caja repartidora

ZDO6H059MSS0000-00STAM190MSS

Conexión

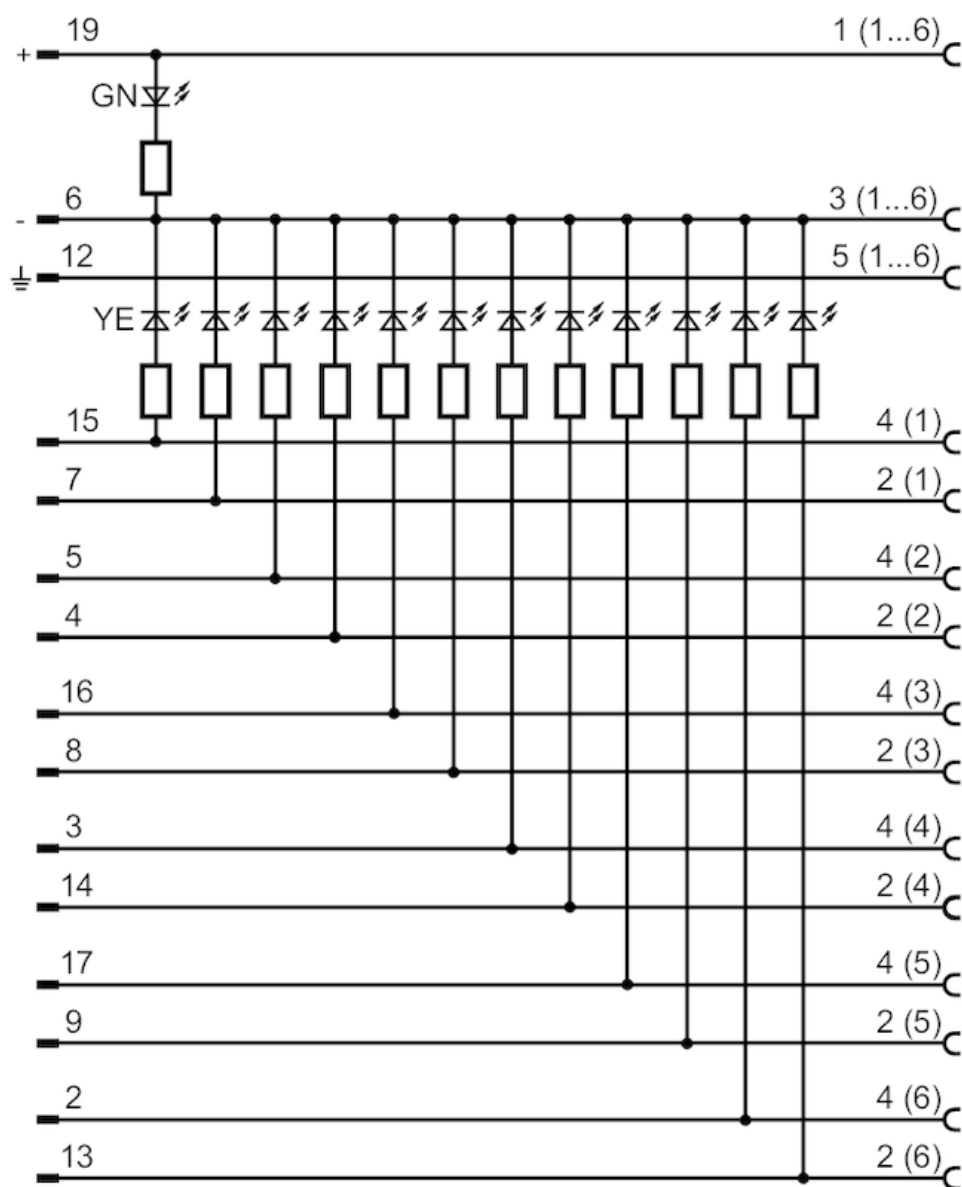

E10946



Caja repartidora

ZDO6H059MSS0000-00STAM190MSS

Conexión eléctrica - punto de conexión

Conector: 6 x M12; codificación: A; cuerpo: TPU; Contactos: dorado; Par de apriete: 0,5 Nm

